


Item No.	Pcs.	Drive	H	Inner
XSBH-S13	13	□6.35(1/4")	T7 T8 T10 T15 T20 T25 T27 T30	10
		□9.5(3/8")	T40 T45 T50 T55	
		□12.7(1/2")	T60	

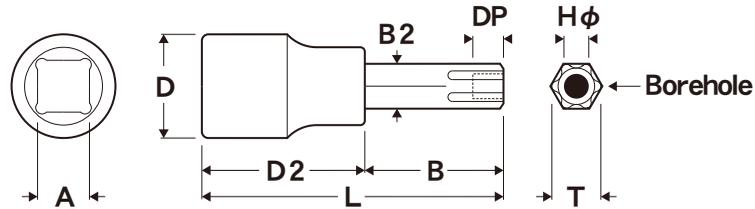

Item No.	A(Drive)	T	D	D2	B	B2	L	Hφ	DP
41XSB-7H	□6.35	T7	15	24	16	6.35	40	0.7	1.5
41XSB-8H	□6.35	T8	15	24	16	6.35	40	0.8	1.5
41XSB-10H	□6.35	T10	15	24	16	6.35	40	1	1.7
41XSB-15H	□6.35	T15	15	24	16	6.35	40	1.3	2
41XSB-20H	□6.35	T20	15	24	16	6.35	40	1.8	2.2
41XSB-25H	□6.35	T25	15	24	16	6.35	40	2.1	2.5
41XSB-27H	□6.35	T27	15	24	16	6.35	40	2.4	3
41XSB-30H	□6.35	T30	15	24	16	6.35	40	2.7	3.2
83XSB-40H	□9.5	T40	17	29	19	8	48	3.2	3.3
83XSB-45H	□9.5	T45	17	29	19	8	48	3.5	3.7
83XSB-50H	□9.5	T50	17	29	19	8	48	3.9	3.8
83XSB-55H	□9.5	T55	19	29	22	10	51	4.9	4.8
21XSB-60H	□12.7	T60	23.5	38	25.5	12	63.5	5.7	8

Tool Type: Torx®

Socket Drive: 6.35mm (1/4") / 9.5mm (3/8") / 12.7mm (1/2")

Measurement Type: Torx®

Additional Information: Standard Length

Additional Information: Borehole