

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- RH
- Wrench icon

MATERIAL

Glass-fibre reinforced polyamide based (PA) technopolymer, grey-black colour, matte finish.

STANDARD EXECUTIONS


 
- **EKK-B:** brass boss, threaded blind hole.
- **EKK-p:** zinc-plated steel threaded stud, chamfered end ISO 4753 (see Technical Data on page A-11).

OTHER EXECUTIONS ON REQUEST

Standard metric threaded holes and studs.

SPECIAL EXECUTIONS ON REQUEST

The knurled knobs EKK-B and EKK-p can anyway be provided in one of the other Ergostyle colours.

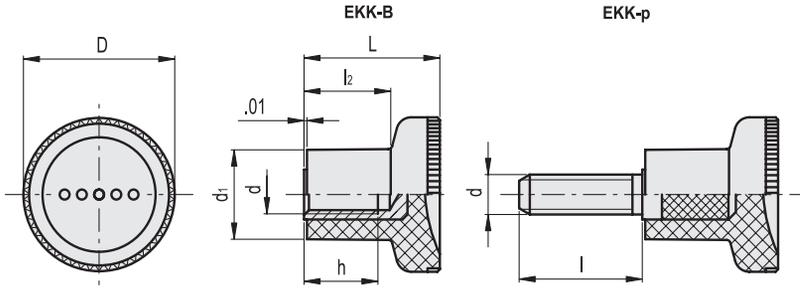

EKK-B

INCH

Code	Description	D	L	d2B	d1	h	l2	ΔΔ
90242081-C1	EKK.16 B-8-32-C1	0.63	0.51	8-32	0.33	0.24	0.33	0.02
90242091-C1	EKK.18 B-8-32-C1	0.71	0.61	8-32	0.41	0.24	0.41	0.01
90242121-C1	EKK.21 B-10-32-C1	0.83	0.71	10-32	0.49	0.39	0.41	0.02
90242211-C1	EKK.25 B-1/4-20-C1	0.98	0.89	1/4-20	0.57	0.47	0.55	0.02
90242311-C1	EKK.31 B-5/16-18-C1	1.22	1.06	5/16-18	0.73	0.59	0.67	0.04

EKK-p

INCH

Code	Description	D	L	d2A	d1	l	l2	ΔΔ
90243131-C1	EKK.21 p-10-32x3/4-C1	0.83	0.71	10-32	0.49	0.750	0.41	0.02
90243231-C1	EKK.25 p-1/4-20x3/4-C1	0.83	0.71	1/4-20	0.49	0.750	0.41	0.02
90243331-C1	EKK.31 p-5/16-18x3/4-C1	1.22	1.06	5/16-18	0.73	0.750	0.67	0.06

Fixed & Revolving handles