

MATERIAL

- Flange: zinc-plated steel with bayonet connector.
- Basket: polypropylene based (PP) technopolymer, black colour.

PACKING RINGS

Cork impregnated MGS based rubber.

MOUNTING




By means of six zinc-plated steel self-tapping screws TC-N10 (Ø 4,8x19) UNI 6951-DIN 7971, supplied.

NOTE

The breather cap to be coupled to the flange is not included in the supply and has to be ordered separately.
Depending on the customer's requirements, can be used breather caps type SFN. (see page 1321), SFP. (see page 1326), SFW. (see page 1340).

SPECIAL EXECUTIONS ON REQUEST

Flange with bayonet connector without basket (FRB).

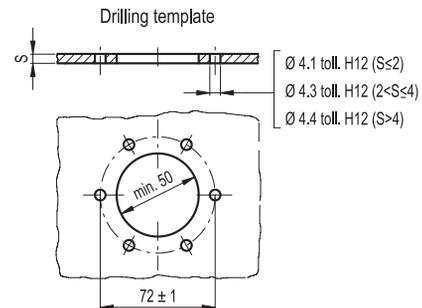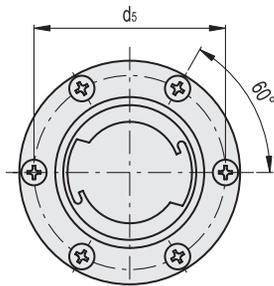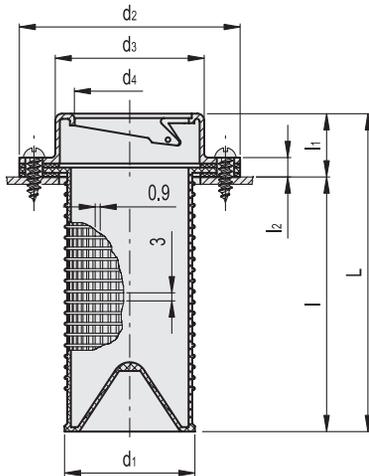

ELESA Original design **if** Hammer

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- RH

METRIC

Code	Description	L	d1	d2	d3	d4	d5	l	l1	l2	⚖
9201	FRB+C	114.5	49	83	58	39	72	94.5	20	7	125