

HRT. | Oil level indicators

push-fit, technopolymer



MATERIAL

Polyamide based (PA) technopolymer, black colour, matte finish.

WINDOW

Transparent polyamide based (PA-T/AR) technopolymer.

CONTRAST SCREEN

White lacquered aluminium with red level line.

PACKING RING

NBR synthetic rubber O-Ring.

MAXIMUM CONTINUOUS WORKING TEMPERATURE

100°C.

FEATURES AND APPLICATIONS

The push-fit assembly is guaranteed by optimised ribbings.

Sealing is guaranteed by the O-ring.

HRT. oil level indicators push-fit are particularly suitable for assembly on reservoirs with limited pressure.

NOTE


For use with other fluids with special additives, please contact ELESA Sales Department.

ASSEMBLY INSTRUCTIONS

Chamfer hole 1x45° and grease slightly the outside surface of the O-ring to make assembly easier.



ELESA Original design

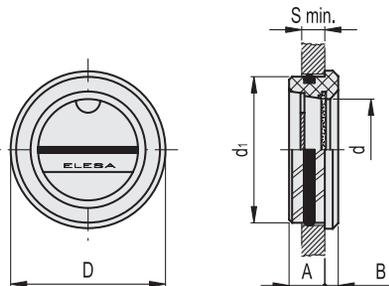

Conversion Table	
1 mm = 0.039 inch	
d1	
mm	inch
26	1.02
32	1.26
38	1.50
60	2.36

METRIC

Code	Description	d1	A	B	D	d	Smin	Mounting hole d1 H11	⚖️
10751	HRT.15-26	26	9	4.5	28	14.5	6	26	6
10756	HRT.20-32	32	10.5	4.5	36	18	8	32	10
10761	HRT.25-38	38	11	5	42	23	8	38	12
10766	HRT.40-60	60	11	5.5	64	40	9	60	29



Accessories for hydraulic systems