

# I.137 | Tapered handles

Duroplast

METRIC

RoHS

PF

+230 °F  
-4 °F

## MATERIAL


Phenolic based (PF) Duroplast, black colour, glossy finish.

## STANDARD EXECUTION

Threaded blind hole.



Conversion Table	
1 mm = 0,039 inch	
L	
mm	inch
62	2.44
69	2.72
79	3.11

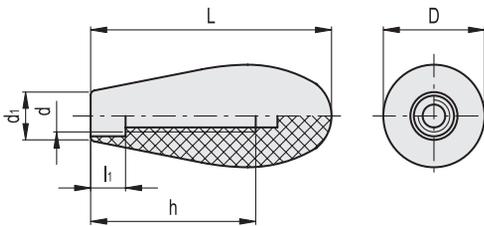

METRIC

Code	Description	D	L	d	d1	h	li	⚖️
19301	I.137/70-M8	29	69	M8	14	45	10	37
19302	I.137/70-M10	29	69	M10	14	45	15	35
19401	I.137/80-M12	35	79	M12	17	55	12	60

