

# I.142 | Tapered handles

Duroplast

METRIC

RoHS

PF

+230 °F  
-4 °F

## MATERIAL

Phenolic based (PF) Duroplast, black colour, glossy finish.


## STANDARD EXECUTION

Threaded blind hole.

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- RH
- 



Conversion Table	
1 mm = 0,039 inch	
L	
mm	inch
60	2.36

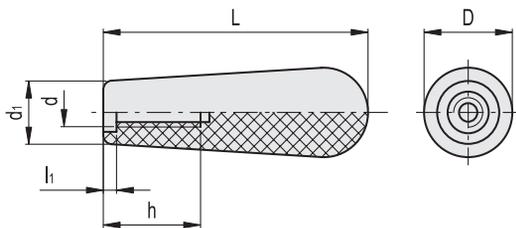

METRIC

Code	Description	D	L	d	d1	h	l1	
19701	I.142/60-M8	20	60	M8	14	20	3	17

Fixed & revolving handles