

# I.167 p | Tapered handles

with protection, Duroplast

METRIC

RoHS

PF

PA


+230 °F  
-4 °F

## MATERIAL

Phenolic based (PF) Duroplast body, polyamide based (PA) technopolymer flange, black colour, glossy finish.

## STANDARD EXECUTION

Zinc-plated steel threaded stud, chamfered flat end according to UNI 947 : ISO 4753 (see Technical data on page A-11).

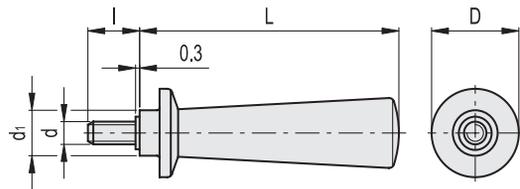

METRIC

Code	Description	D	L	d <sub>6g</sub>	d <sub>1</sub>	l	⚖
20306	I.167/103 p-M8x16	35	104	M8	18	16	90
20311	I.167/103 p-M8x25	35	104	M8	18	25	94

### Conversion Table

1 mm = 0.039 inch

L	
mm	inch
65	2.56
80	3.15
90	3.54
104	4.09

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15

Fixed & revolving handles