

I.280 Cylindrical handles

Duroplast

INCH



PF

+230 °F
-4 °F


- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- RH
-

MATERIAL

Phenolic based (PF) Duroplast, black colour, glossy finish.

STANDARD EXECUTION

Threaded blind hole.

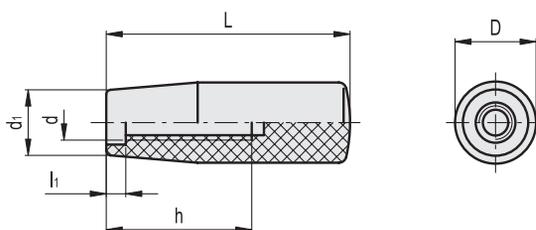

INCH

Code	Description	D	L	d	d1	h	li	
921601	I.280/40-1/4-20	0.71	1.57	1/4-20	0.59	0.98	0.14	0.03
921702	I.280/50-5/16-18	0.83	1.97	5/16-18	0.67	1.38	0.3	0.04
921802	I.280/65-3/8-16	0.91	2.56	3/8-16	0.75	1.57	0.3	0.07
921901	I.280/80-3/8-16	1.02	3.15	3/8-16	0.83	2.17	0.28	0.1
922002	I.280/90-1/2-13	1.1	3.54	1/2-13	0.87	2.28	0.31	0.14

Fixed & Revolving handles