

# I.622 | Tapered handles

Technopolymer



- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18

## MATERIAL

Polyamide based (PA) technopolymer, in Elecolors colours, glossy finish.

## STANDARD EXECUTION


Threaded blind hole.

## SPECIAL EXECUTIONS ON REQUEST

Different RAL colours.



ELESA Original design

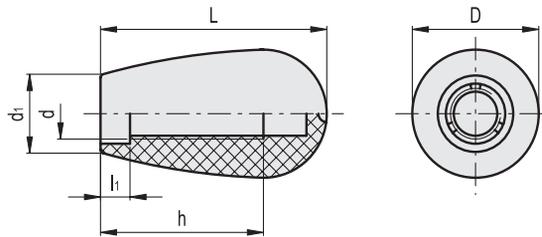

Conversion Table	
1 mm = 0.039 inch	
D	
mm	inch
16	0.63
20	0.79
26	1.02
34	1.34

\*Complete with colour index, example: 120912 I.622/25-M6-C2

C9 C2 C3 C4 C5 C6 C17  
 RAL9005 RAL2004 RAL7035 RAL1021 RAL5024 RAL3000 RAL6017



Code C9	Code C2	Code C3	Code C4	Code C5	Code C6	Code C17	Description	D	L	d	d1	h	l1	⚖️
120911	120912	120913	120914	120915	120916	120917	I.622/25-M6-*	16	25	M6	12	16	3.5	4
120951	120952	120953	120954	120955	120956	120957	I.622/30-M8-*	20	32	M8	14	20	3.5	7
120991	120992	120993	120994	120995	120996	120997	I.622/40-M8-*	26	42	M8	17	30	5	18
121001	121002	121003	121004	121005	121006	121007	I.622/40-M10-*	26	42	M10	17	30	5	16
121061	121062	121063	121064	121065	121066	121067	I.622/55-M10-*	34	54.5	M10	21	35	8	34
121071	121072	121073	121074	121075	121076	121077	I.622/55-M12-*	34	54.5	M12	21	35	8	32

Fixed & Revolving handles