

I.622 | Tapered handles

Technopolymer

INCH

RoHS

PA

+194 °F
-4 °F

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- RH
- Wrench icon

MATERIAL

Polyamide based (PA) technopolymer, black colour, glossy finish.

STANDARD EXECUTION


Threaded blind hole.

SPECIAL EXECUTIONS ON REQUEST

Different RAL colours.



ELESA Original design

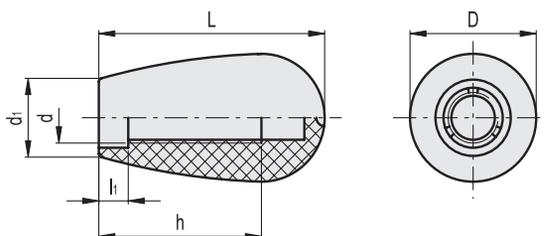

INCH

Code	Description	D	L	d	d1	h	li	△
920911	I.622/25-1/4-20	0.63	0.98	1/4-20	0.47	0.63	0.14	0.01
920921	I.622/30-5/16-18	0.79	1.26	5/16-18	0.55	0.79	0.14	0.02
920931	I.622/40-3/8-16	1.02	1.65	3/8-16	0.67	1.18	0.2	0.04
920941	I.622/55-1/2-13	1.34	2.15	1/2-13	0.83	1.38	0.31	0.07

Fixed & Revolving handles