

I.631+x

# Revolving handle

Technopolymer

METRIC

RoHS

PP

+176 °F  
+32 °F

## MATERIAL

High-resilience polypropylene based (PP) technopolymer, black colour, matte finish.

## STANDARD EXECUTION


Zinc-plated steel shank, hexagon socket at threaded end.



Fixed & revolving handles



Conversion Table	
1 mm = 0.039 inch	
L	
mm	inch
20	0.79
23	0.91
63	2.48

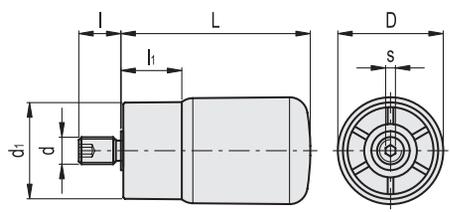

METRIC

Code	Description	D	L	d <sub>6g</sub>	d <sub>1</sub>	l	l <sub>1</sub>	s	⚖
122622	I.631/65+x-M10	35	63	M10	32	17	19	5	79