

I.701+x | Revolving handles

Technopolymer

METRIC

RoHS

PA

+194 °F
-4 °F

MATERIAL


Polyamide based (PA) technopolymer, black colour, matte finish.

STANDARD EXECUTION

Zinc-plated steel shank, hexagon socket at threaded end.



Conversion Table	
1 mm = 0.039 inch	
L	
mm	inch
20	0.79
23	0.91
63	2.48

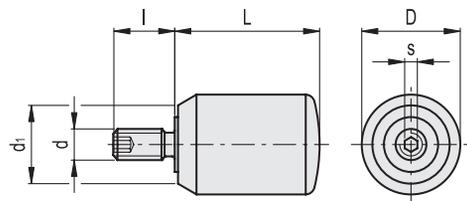

METRIC

Code	Description	D	L	d6g	d1	l	s	⚖
24974	I.701/20+x-M4	13.5	20	M4	11	8	2	7
24979	I.701/20+x-M5	13.5	20	M5	11	10	2.5	10
24980	I.701/23+x-M5	16	23	M5	12.5	10	2.5	12

- 1
 - 2
 - 3
 - 4
 - 5
 - 6
 - 7
 - 8
 - 9
 - 10
 - 11
 - 12
 - 13
 - 14
 - 15
- RH

Fixed & revolving handles