

I.780 | Cylindrical handles

Technopolymer

METRIC

RoHS

PA

+230°F
-4°F

MATERIAL


Glass-fibre reinforced polyamide based (PA) technopolymer, black or red colour, matte finish.

MOUNTING

Threaded blind hole.



ELESA Original design

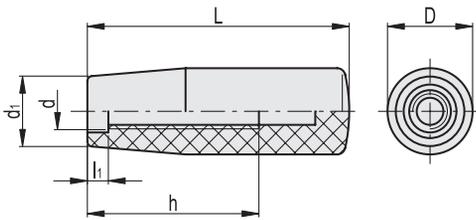

■ C9 RAL9005 ■ C6 RAL3000

METRIC

Code	Description	D	L	d	d1	h	li	⚖
124791	I.780/65-M8-C9	24.5	65	M8	20.5	30	7	34
124801	I.780/65-M8-C6	24.5	65	M8	20.5	30	7	34
124792	I.780/65-M10-C9	24.5	65	M10	20.5	40	7	34
124806	I.780/80-M8-C9	26.5	80	M8	21	40	7	45
124807	I.780/80-M10-C9	26.5	80	M10	21	55	7	45
124812	I.780/80-M10-C6	26.5	80	M10	21	55	7	45
124808	I.780/80-M12-C9	26.5	80	M12	21	55	7	45
124817	I.780/90-M10-C9	28.5	90	M10	22.5	55	7	50
124818	I.780/90-M12-C9	28.5	90	M12	22.5	58	7	50
124822	I.780/90-M12-C6	28.5	90	M12	22.5	58	7	50

Conversion Table 1 mm = 0.039 inch	
L	
mm	inch
65	2.56
80	3.15
90	3.54
104	4.09



Fixed & revolving handles