

MATERIAL

Polyethylene (PE), RAL 9005 (C9) black colour or RAL 7042 (C34) grey colour, satin finish.

STANDARD EXECUTIONS

- **NIL-Q**: for square tubes.
- **NIL-R**: for rectangular tubes.
- **NIL-T**: for round tubes.

FITTING


Their fitting to the round, square or rectangular section tube or profile ends can be made either by hand or by a mallet.

SPECIAL EXECUTIONS ON REQUEST

RAL 9003 white coloured inserts.



NIL.Q

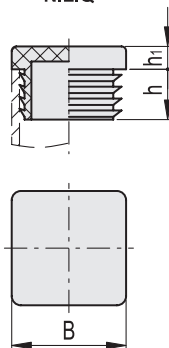

* Complete with colour index, example: 435010-C9 NIL.T-10-C9

C9
RAL9005


C34
RAL7042

NIL.Q

Code	Description	B	h	h1	External	Thickness
435210-*	NIL.Q-10-*	10	12	4	10	0,8+2,5
435212-*	NIL.Q-12-*	12	12	4	12	1+2
435213-*	NIL.Q-13-*	13	12	4	13	0,5+2
435215-*	NIL.Q-15-*	15	11,5	3	15	1+2
435216-*	NIL.Q-16-*	16	11,5	5	16	1+2,5
435218-*	NIL.Q-18-*	18	11,5	5	18	1,5+3
435220-*	NIL.Q-20-*	20	11,5	5	20	1+3
435222-*	NIL.Q-22-*	22	12	5	22	1+3,5
435225-*	NIL.Q-25-*	25	11,5	5	25	1+3
435228-*	NIL.Q-28-*	28	11,5	5	28	1+3
435230-*	NIL.Q-30-*	30	11,5	5	30	1+3
435232-*	NIL.Q-32-*	32	11,5	5	32	1+3,5
435234-*	NIL.Q-34-*	34	14,5	5	34	1+3
435235-*	NIL.Q-35-*	35	11,5	5	35	1+3
435238-*	NIL.Q-38-*	38	14,5	5	38	1+3,5
435240-*	NIL.Q-40-*	40	14,5	5	40	1+3
435245-*	NIL.Q-45-*	45	14,5	5	45	1+3

NIL.Q

Code	Description	B	h	h1	External	Thickness
435250-*	NIL.Q-50-*	50	14,5	5	50	1+2,5
435370-*	NIL.Q-50-2.6-*	50	24	5,5	50	2.6+4
435255-*	NIL.Q-55-*	55	14,5	5	55	2+4,5
435260-*	NIL.Q-60-*	60	15	5	60	1,5+3,5
435265-*	NIL.Q-65-*	65	21	5	65	1+3
435270-*	NIL.Q-70-*	70	22	5	70	2+5
435275-*	NIL.Q-75-*	75	21	6	75	2+4,5
435276-*	NIL.Q-76,2-*	76.2	21	6	76.2	2,5+5
435280-*	NIL.Q-80-*	80	21	6	80	1,5+4
435290-*	NIL.Q-90-*	90	21	6	90	3+5
435295-*	NIL.Q-95-*	95	21,5	6	95	3,5+5,5
435300-*	NIL.Q-100-*	100	21	7	100	1+4
435310-*	NIL.Q-110-*	110	24	6	110	3+5
435320-*	NIL.Q-120-*	120	30	5	120	2,5+6
435340-*	NIL.Q-140-*	140	34	3	140	4+7
435350-*	NIL.Q-150-*	150	28	7	150	5+8

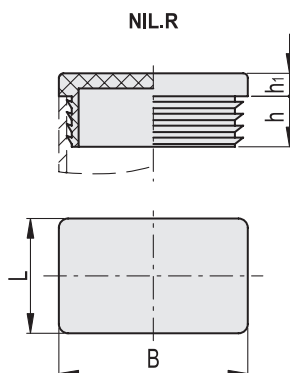


* Complete with colour index, example: 435410-C9 NIL.R-20x10-C9

C9
RAL9005

C34
RAL7042

NIL-R							METRIC						
Code	Description	B	L	h	h1	External Thickness							
435410-*	NIL.R-20x10-*	20	10	12	3	20x10	0,8÷2						
435411-*	NIL.R-20x15-*	20	15	11.5	5	20x15	1÷2						
435430-*	NIL.R-25x10-*	25	10	11.5	3	25x10	0,8÷2						
435431-*	NIL.R-25x15-*	25	15	11.5	5	25x15	1÷2,5						
435432-*	NIL.R-25x20-*	25	20	11.5	5	25x20	1÷3						
435450-*	NIL.R-30x10-*	30	10	11.5	3	30x10	1÷2						
435451-*	NIL.R-30x15-*	30	15	11.5	5	30x15	1÷2,5						
435452-*	NIL.R-30x20-*	30	20	11.5	5	30x20	1÷3						
435470-*	NIL.R-35x10-*	35	10	11.5	3.5	35x10	1÷2						
435471-*	NIL.R-35x20-*	35	20	11.5	5	35x20	1÷2,5						
435472-*	NIL.R-35x25-*	35	25	11.5	5	35x25	1÷3						
435490-*	NIL.R-40x15-*	40	15	12	5	40x15	1÷2						
435491-*	NIL.R-40x20-*	40	20	12	5	40x20	1÷3						
435492-*	NIL.R-40x25-*	40	25	11.5	5	40x25	1÷3						
435493-*	NIL.R-40x30-*	40	30	11	5	40x30	1÷3						
435494-*	NIL.R-40x35-*	40	35	12	5	40x35	1÷3						
435510-*	NIL.R-45x15-*	45	15	11	5	45x15	1,5÷2						
435511-*	NIL.R-45x20-*	45	20	11.5	5	45x20	1÷3						
435512-*	NIL.R-45x25-*	45	25	12	5	45x25	1÷3						
435513-*	NIL.R-45x30-*	45	30	12	5	45x30	1÷2,5						
435514-*	NIL.R-45x35-*	45	35	12	5	45x35	1÷3,5						
435530-*	NIL.R-50x20-*	50	20	15	5	50x20	1÷3						
435531-*	NIL.R-50x25-*	50	25	11.5	5	50x25	1÷3						
435532-*	NIL.R-50x30-*	50	30	12	5	50x30	1÷3						
435533-*	NIL.R-50x35-*	50	35	14.5	5	50x35	1÷3,5						
NIL-R							METRIC						
Code	Description	B	L	h	h1	External Thickness							
435534-*	NIL.R-50x40-*	50	40	15	5	50x40	1,5÷3						
435550-*	NIL.R-60x20-*	60	20	14.5	5	60x20	1÷3						
435551-*	NIL.R-60x25-*	60	25	15	5	60x25	1÷3						
435552-*	NIL.R-60x30-*	60	30	15	5	60x30	1÷2,5						
435553-*	NIL.R-60x35-*	60	35	15	5	60x35	1,5÷3,5						
435554-*	NIL.R-60x40-*	60	40	14	5	60x40	1÷3						
435555-*	NIL.R-60x45-*	60	45	15	5	60x45	1,5÷4						
435556-*	NIL.R-60x50-*	60	50	14.5	5	60x50	1,5÷3,5						
435570-*	NIL.R-70x20-*	70	20	19	5	70x20	1÷3,5						
435571-*	NIL.R-70x25-*	70	25	18	5	70x25	1,5÷2,5						
435572-*	NIL.R-70x30-*	70	30	15	5	70x30	1÷3						
435573-*	NIL.R-70x35-*	70	35	15	5	70x35	1,5÷3,5						
435574-*	NIL.R-70x40-*	70	40	20	5	70x40	1,5÷3						
435590-*	NIL.R-80x20-*	80	20	18	5	80x20	1÷3						
435591-*	NIL.R-80x30-*	80	30	14.5	5	80x30	1÷2,5						
435592-*	NIL.R-80x40-*	80	40	14.5	5	80x40	1÷3						
435593-*	NIL.R-80x50-*	80	50	22	5	80x50	1,5÷4						
435594-*	NIL.R-80x60-*	80	60	25	5	80x60	1,5÷3,5						
435610-*	NIL.R-90x20-*	90	20	14.5	5	90x20	1÷2,5						
435611-*	NIL.R-90x40-*	90	40	15	5	90x40	2÷4						
435612-*	NIL.R-90x50-*	90	50	22	5	90x50	2÷4,5						
435630-*	NIL.R-100x30-*	100	30	15	5	100x30	1,5÷3,5						
435631-*	NIL.R-100x40-*	100	40	14.5	5	100x40	1,5÷4						
435632-*	NIL.R-100x50-*	100	50	24	5	100x50	1,5÷4,5						
435633-*	NIL.R-100x60-*	100	60	25	6	100x60	1,5÷4,5						

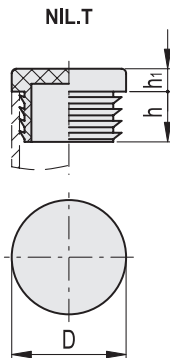

* Complete with colour index, example: 435010-C9 NIL.T-10-C9

C9 **C34**
RAL9005 RAL7042

NIL.T							NIL.T						
▼							▼						
Code	Description	D	h	h1	External	Thickness	Code	Description	D	h	h1	External	Thickness
435010-*	NIL.T-10-*	10	11	3.5	10	1+2	435040-*	NIL.T-40-*	40	11.5	5	40	1+3
435012-*	NIL.T-12-*	12	11	3.5	12	1+2	435042-*	NIL.T-42-*	42	11.5	5	42	1+3
435013-*	NIL.T-13-*	13	11	4	13	1+2	435045-*	NIL.T-45-*	45	11	5	45	1+3
435014-*	NIL.T-14-*	14	11.5	5	14	1+2	435046-*	NIL.T-46-*	46	11.5	5	46	1,5+3,5
435015-*	NIL.T-15-*	15	11.5	3	15	1+2	435048-*	NIL.T-48-*	48	11.5	5	48	1,2+3,6
435016-*	NIL.T-16-*	16	11	5	16	1+2	435050-*	NIL.T-50-*	50	14.5	5	50	1+2,5
435018-*	NIL.T-18-*	18	11.5	5	18	1+2	435150-*	NIL.T-50-2.5-*	50	11.5	5	50	2,5+4,5
435019-*	NIL.T-19-*	19	11.5	5	19	1+2,5	435052-*	NIL.T-52-*	52	14.5	5	52	1,5+3,5
435020-*	NIL.T-20-*	20	11.5	5	20	1+2,5	435055-*	NIL.T-55-*	55	11.5	5	55	1+3
435022-*	NIL.T-22-*	22	11.5	5	22	1+2	435155-*	NIL.T-55-3-*	55	14.5	5	55	3+5
435023-*	NIL.T-23-*	23	11.5	5	23	1+2,5	435060-*	NIL.T-60-*	60	14.5	5	60	1,5+3
435024-*	NIL.T-24-*	24	11.5	5	24	1+2,5	435160-*	NIL.T-60-3-*	60	17.5	5	60	3+5
435025-*	NIL.T-25-*	25	11.5	5	25	1+3	435065-*	NIL.T-65-*	65	14.5	5	65	1,5+3,5
435026-*	NIL.T-26-*	26	11.5	5	26	1+3	435070-*	NIL.T-70-*	70	21	5	70	1,5+3,5
435027-*	NIL.T-27-*	27	11.5	5	27	1+3	435075-*	NIL.T-75-*	75	21.5	6	75	1+3,5
435028-*	NIL.T-28-*	28	11.5	5	28	1+3	435076-*	NIL.T-76-*	76	21.5	6	76	1,6+4
435030-*	NIL.T-30-*	30	11.5	5	30	1+2,5	435080-*	NIL.T-80-*	80	22	5	80	1,5+3
435032-*	NIL.T-32-*	32	12	5	32	1+3	435085-*	NIL.T-85-*	85	21	6	85	1,5+4
435034-*	NIL.T-34-*	34	11.5	5	34	1+3	435088-*	NIL.T-88-*	88	21.5	6	88	1,5+4
435035-*	NIL.T-35-*	35	11.5	5	35	1+3	435090-*	NIL.T-90-*	90	21	6	90	1,5+5
435036-*	NIL.T-36-*	36	11.5	5	36	1+3	435095-*	NIL.T-95-*	95	21	6	95	1,5+4
435037-*	NIL.T-37-*	37	11.5	5	37	1+3	435110-*	NIL.T-100-*	100	28.5	6	100	2+4,5
435038-*	NIL.T-38-*	38	11.5	5	38	1+3,5							