

P.111+x | Spherical revolving handles

Duroplast

METRIC

RoHS

PF

+230 °F
-4 °F

MATERIAL


Phenolic based (PF) Duroplast handle, black colour, glossy finish.

STANDARD EXECUTION

Zinc-plated steel threaded shank, two flat faces for fitting with 12 mm spanner.



Conversion Table	
1 mm = 0,039 inch	
D	
mm	inch
37	1.46
47	1.85

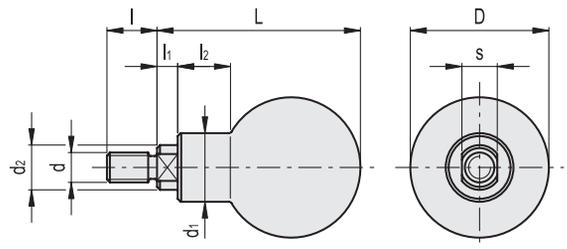

METRIC

Code	Description	D	L	d _{6g}	d ₁	d ₂	l	l ₁	l ₂	s	△
45981	P.111/37+x-M8	37	54	M8	18	15	15	7	13	12	55
46011	P.111/47+x-M10	47	69	M10	23	15	17	7	17	12	130