



# SURFACE™ QUIETCLEAN® UPRIGHT

SC9180B

MENU


 
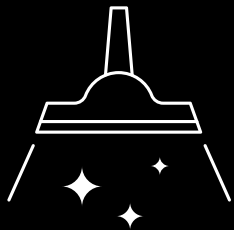



CRI BRONZE SEAL  
OF APPROVAL



LEED  
QUALIFIED

The SURFACE™ QuietClean® upright is CRI Bronze certified for an exceptional clean on multiple surfaces, including hard woods and carpets. QuietClean® model is quiet at just 67 dBA with a sealed HEPA system for 24/7 cleaning performance. Turn the brushroll on or off or use the wand with retractable dusting brush for multi-surface cleaning.

 <b>CRI BRONZE SEAL OF APPROVAL</b>	 <b>MULTI-SURFACE CLEANING</b>	 <b>PERFORMANCE</b>
<b>quiet CLEAN</b> 67 DBA	 <b>LEED QUALIFIED</b>	

SPECIFICATIONS			
<b>MFG#</b>	SC9180B	<b>CLEANING WIDTH</b>	13"
<b>MOTOR</b>	11.3 amp	<b>CORD LENGTH</b>	50' Pigtail
<b>CFM</b>	135	<b>SOUND</b>	67 dBA
<b>FILTRATION</b>	Sealed HEPA	<b>BRUSH ROLL</b>	16101-1
<b>DUST CONTAINMENT</b>	Disposable Bag	<b>BAG</b>	SD (63262B, 63989B)
<b>DUST CAPACITY</b>	4 qt.	<b>BELT</b>	77133
<b>CLEANING TOOLS</b>	Telescopic wand with permanently attached retractable dusting brush.	<b>FILTER</b>	68910-4
PACKAGING			
<b>UPC</b>	0 23169 12197 3	<b>PACKAGE WEIGHT</b>	28.8 lbs.
<b>PRODUCT WEIGHT</b>	20 lbs.	<b>PACKAGE DIMENSIONS</b>	36.25" x 15.5" x 8.25"
<b>WARRANTY</b>	2 Years - Parts & Labor		