



VOYAGER 6200 UC

Comfort. Versatility. Performance.


Bluetooth® neckband headset with earbuds.

Professional-grade audio

VOYAGER 6200 UC

Voyager 6200 UC is a Bluetooth® neckband headset with earbuds made for the professional. Transitioning to your next conversation is easy: Connect with colleagues working remotely, listen to music to focus distraction-free or drop an earbud to tune in to the conversation around you. Voyager 6200 UC has the versatility to go beyond the office, for outstanding audio every time, everywhere.

KEY FEATURES

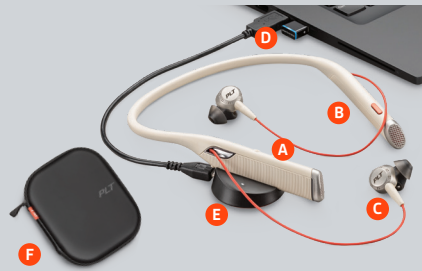

- A** On-demand active noise canceling (ANC)
- B** Dedicated mute button
- C** Comfort-fit earbuds
- D** BT600 USB adapter
- E** Desktop charging stand
- F** Travel case

For more information about the Voyager 6200 UC or other products, please visit plantronics.com.

PLANTRONICS CUSTOMER CARE

Backed by Plantronics industry-leading global service and support. plantronics.com/contactsupport.

TOP FEATURES

- Boomless design features Plantronics clear talk technology, four omnidirectional microphones and enhanced noise canceling, optimizing your voice and minimizing background noise.
- On-demand passive and active noise canceling (ANC) block out distractions so you can focus on your call or work.
- Premium wireless hi-fi stereo headset works seamlessly across multiple applications on desktops, Bluetooth®-enabled desk phones, laptops, mobile phones and tablets.
- Neckband vibrates to alert you of incoming calls; so there's no need to look at your mobile phone.
- Switch from stereo to mono to hear your surroundings simply by dropping an earbud, or remove both earbuds for face-to-face conversations.
- Wideband audio provides high-quality PC telephony and is compatible with smartphones enabled for HD voice.
- Dynamic mute alert senses when you start to talk while the headset is on mute and sends you a voice prompt.
- Plantronics Manager Pro, software-as-a-service that is sold separately, enables your IT team to gain insight into every Plantronics headset being used company-wide.

SPECIFICATIONS

Listen/talk/standby time	Up to 16 hours listen, 9 hours talk and 14 days standby time
Roaming range	Up to 98 ft/30 m, with Class 1 enabled Bluetooth device
Battery capacity	340 mAh minimum
Battery type	Rechargeable, non-replaceable lithium ion polymer
Charge time	1.5 hours for full charge
Bluetooth technology	Bluetooth v4.1 Headset Profile (HSP) 1.2 and Hands-Free Profile (HFP) 1.6 (wideband HD voice); Class 1 BT radio
Audio profiles	Advanced Audio Distribution Profile (A2DP) 1.2, AVRCP 1.5
Codecs	Classic; Low latency, APTx
Receive audio performance	Active noise canceling (ANC)
Receive frequency response	20 Hz–20 kHz (hi-fi stereo and stereo telephony)
Hearing protection	SoundGuard DIGITAL: protects against sound levels above 118dBA; G616 anti-startle (during calls) detects and eliminates any large sudden increase in signal level; Time-weighted average prevents average daily noise exposure from exceeding 85dBA*
Microphone and technology	Boomless design features Plantronics clear talk technology and four omnidirectional microphones with digital signal processing (DSP)
Weight	0.12 lbs/56 g
Call controls	Call answer/end, mute, volume +/-
Media controls	Mute, play, pause, track forward/back
Voice and other alerts	Enhanced voice alerts announce talk time remaining, mute and connection status. Neckband vibrates to alert incoming call
Model	B6200 : Certified for Skype for Business. Built for UC applications and softphones from Avaya, Cisco, Skype and others. See software compatibility guide at plantronics.com/us/support/supported-softphones
Applications supported	Plantronics Hub desktop version is available for Windows/Mac, mobile version offered on Android and iOS

*Requires Plantronics Hub software to enable SoundGuard DIGITAL features.