


CURRENT TRANSFORMER INTEGRATORS

MOD Series

DIN Rail Mount 1, 2, and 3 phase Rogowski Coil CT Integrators.

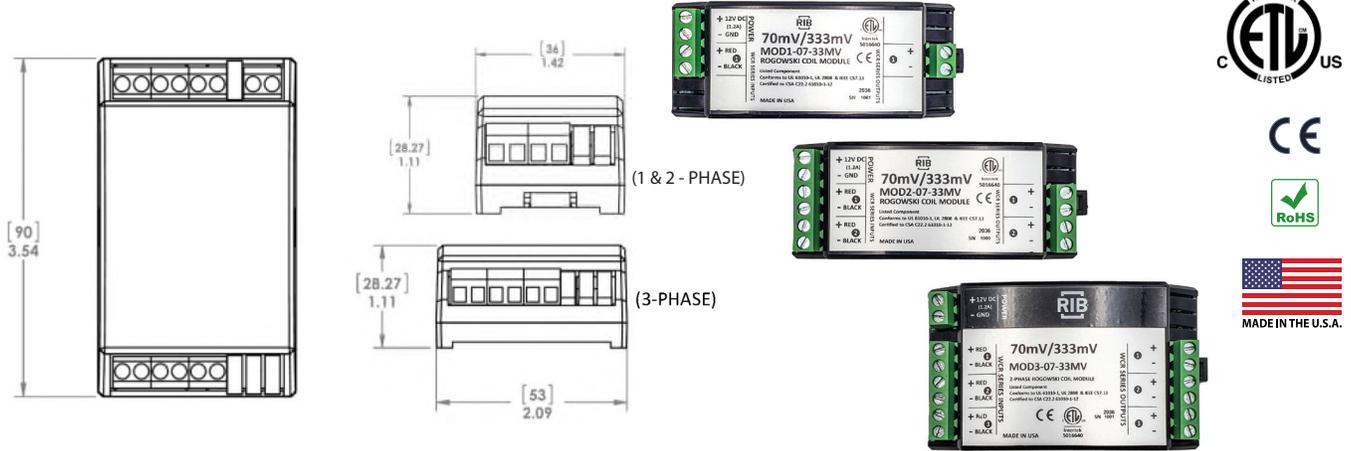

SPECIFICATIONS - FOR USE WITH ROPE SERIES

- Environment:** Indoor Use Only
5 to 149° F (-15 to 65°C)
90% relative humidity
- Input:** 70mV AC 60 Hz
- Output:** 0.333Vac
- Accuracy:** 0.5% (typical)
- Linearity:** 10%-120%
- Polarity:** Red-Hi, Black-Low
- Frequency range:** 40-400 Hz
- Power Supply Requirements:** 12 Vdc @ 1.2A or 24 Vdc @ 0.6A
- Approvals:** ETL Listed, CE, RoHS

MOD SERIES			
Model #	Phases	Ratio	Accuracy (%)
MOD1-07-33MV	1	70mV/333mV	0.5
MOD2-07-33MV	2	70mV/333mV	0.5
MOD3-07-33MV	3	70mV/333mV	0.5

APPLICATION - FOR USE WITH ROPE SERIES

