


**AC & DC POWER SUPPLY: 120 VAC TO 24 VAC & 24 VDC**

**PSH100A100AB10-DC**

Enclosed Dual Power Supplies, 100 VA, 120 to 24 Vac and 120 to 24 Vdc @ 2.5 Amp, Class 2

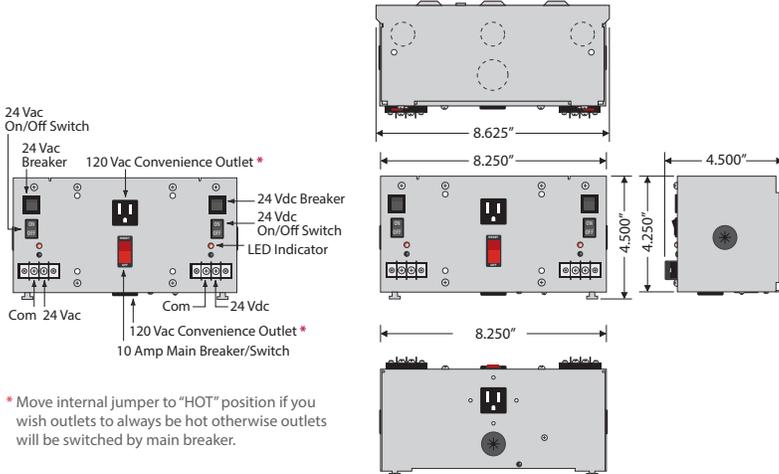

\* Move internal jumper to "HOT" position if you wish outlets to always be hot otherwise outlets will be switched by main breaker.



**SPECIFICATIONS**

- Over Current Protection:** Circuit Breaker
- Frequency:** 50/60 Hz
- 24 Vac ON/OFF:** On / Off Switch & Breaker
- 24 Vdc ON/OFF:** On / Off Switch & Breaker
- Main Breaker ON/OFF:** Switch / Breaker (10 Amp)  
 (Kills power to entire unit: Outlets, Aux. Output, 24 Vac, & 24 Vdc)\*
- Total Combined Output** 9A
- Max. Ambient Temperature:** 40° C
- Approvals:** Class 2 (UL Approved UL5085-3), UL508, C-UL, CE, RoHS, FCC
- Dimensions:** 4.500" H x 8.625" W x 4.500" D
- Origin:** Made of US and non-US parts

- Input Wires:** Input Power Wires  
 BLK: 120 Vac  
 WHT: Neutral  
 GRN: Ground

- Outlet Wires  
 BLK: 120 Vac  
 WHT: Neutral  
 GRN: Ground

- Output Wires:** Auxiliary Output  
 BLU: 120 Vac

- Notes:**  
 • Output derating may exceed 20% due to elevated ambient temperature or heat buildup in device over time.