




TRANSFORMER

TR100VA001US

Transformer 96 VA, 120 to 24 Vac, Circuit Breaker, Foot and Single Threaded Hub Mount

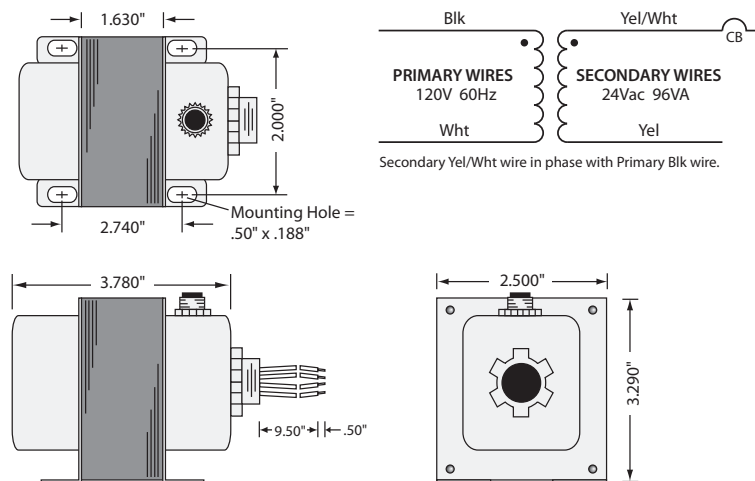

SPECIFICATIONS

VA Rating: 96

Frequency: 50/60 Hz

Mounting: Foot & Single Threaded Hub

Over Current Protection: Circuit Breaker

Dimensions: 3.780" x 2.500" x 3.290" (w/ .500" NPT Hub)

Wire Length: 9.5" Typical w/ .5" Strip

Operating Temperature: -30 to 140° F

MTBF: 100,000 Hours @ 77° F

Construction: Split-Bobbin

Approvals: Class 2 UL5085-3 Listed, C-UL, CE, RoHS