
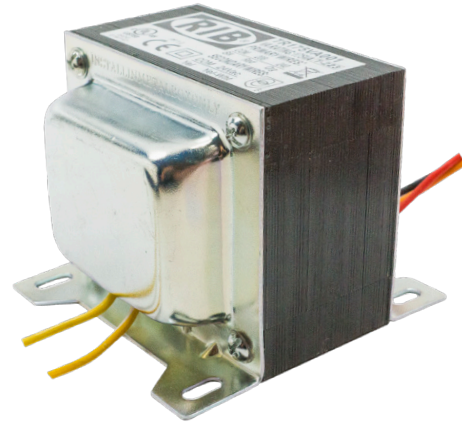


TRANSFORMER

TR175VA001

Transformer 175 VA, 240/208 to 24 Vac, Foot Mount, Dual Bottom Openings

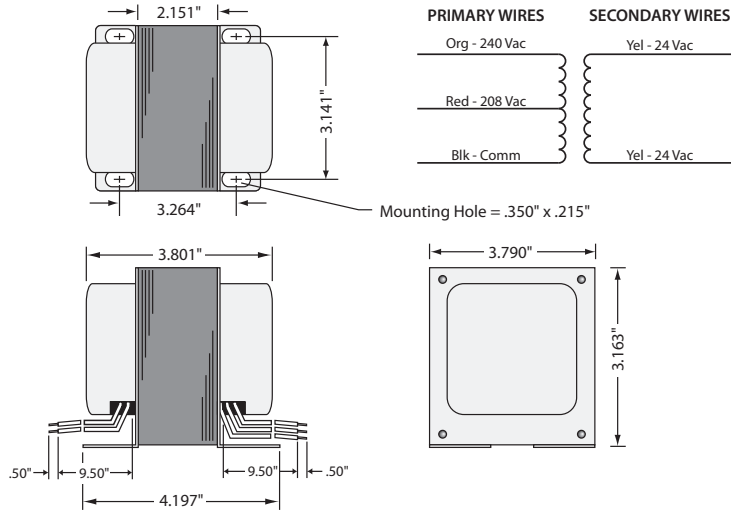

SPECIFICATIONS

- VA Rating:** 175
- Frequency:** 50/60 Hz
- Mounting:** Foot
- Over Current Protection:** None
- Dimensions:** 3.801" x 3.790" x 3.163"
- Wire Length:** 9.5" Typical w/ .5" Strip
- Operating Temperature:** -30 to 140° F
- MTBF:** 100,000 Hours @ 77° F
- Construction:** Split-Bobbin
- Approvals:** UL5085-2 Listed General Purpose, C-UL, CE, RoHS