


# Frost Proof Yard Hydrants

Lead Free


## AWP00001K

- Use for irrigation, equipment cleaning, lawn care and more
- Heavy-duty cast iron head and handle
- Easily replace rod, plunger, seat and linkage without digging
- Steel, zinc-plated 1" diameter pipe with 3/4" FNPT connection
- Brass foot valve, hose adapter and pivot connector
- IAPMO Certified Lead Free to NSF/ANSI 372-2016, Drinking Water System Components

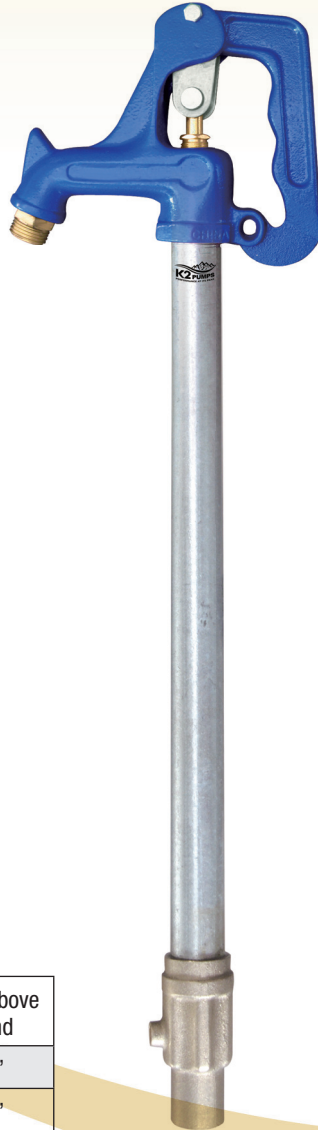

## Parts/Accessories

**PAWP00002K**  
Complete Head Assembly

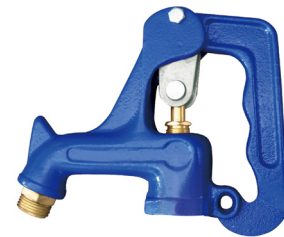

**PAWP00001K**  
Hydrant Repair Kit



## Specifications

Model No.	Overall Pipe Length	Bury Depth	Height Above Ground
AWP00001K-1	3.25'	1'	2.25'
AWP00001K-2	4.25'	2'	2.25'
AWP00001K-3	5.25'	3'	2.25'
AWP00001K-4	6.25'	4'	2.25'
AWP00001K-5	7.25'	5'	2.25'
AWP00001K-6	8.25'	6'	2.25'
AWP00001K-8	10.25'	8'	2.25'