



TECHNICAL DATA

Features

- Large LCD display
- Quick response with high accuracy
- Stainless steel platform
- User selectable grams, pounds and ounces
- Full tare capacity
- Low battery and overload indicator
- Includes batteries

Specifications

Measuring Range:	5000g / 9lbs 15oz
Accuracy:	+/-1% of rdg
Resolution:	0.1oz / 1g (min 0.2oz / 2g start)
Display:	LCD 55 mm x 21 mm
Units:	g / lbs / oz
Tare:	Yes
Auto Power Off:	Yes
Low Battery Indicator:	Yes
Over Load Indicator:	Yes
Power Supply:	2 x AAA Batteries
Platform Size:	8.3 x 5.9 x 0.5" (210 x 150 x 12mm)
Product Certification:	CE, RoHS
Operating Temp.:	41 to 104°F (5 to 40°C)
Storage Temp.:	-4 to 140°F (-20 to 60°C)

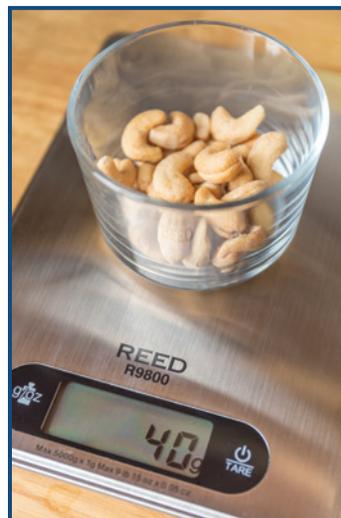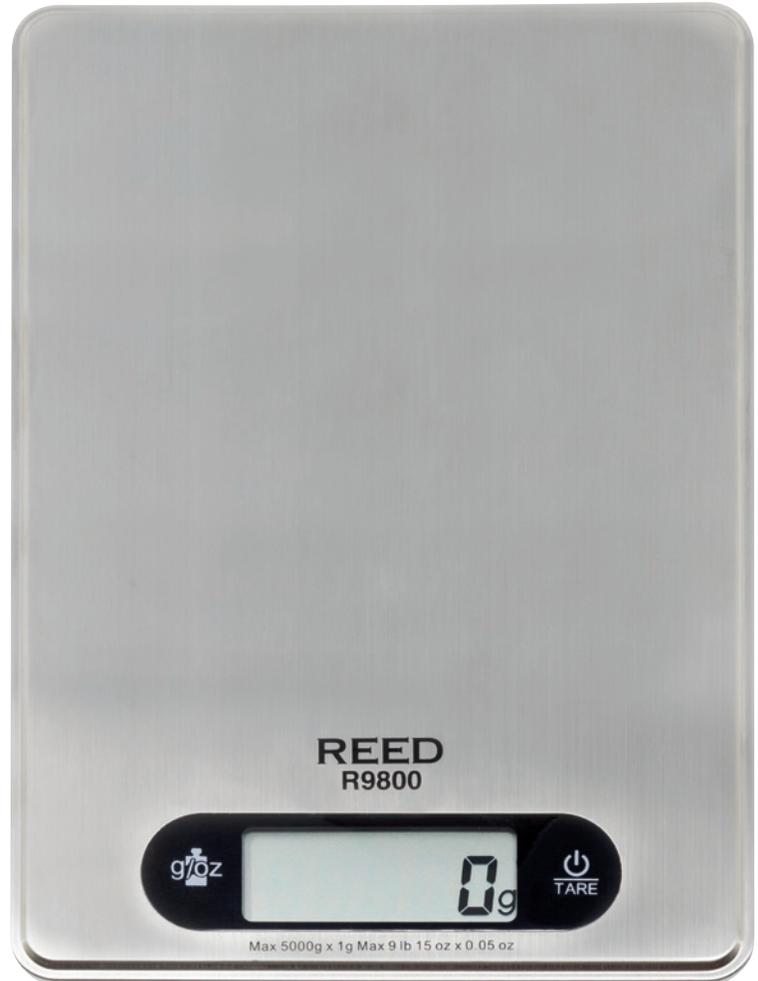

Model	Description
R9800	Digital Portion Control Scale