

Glenwall® Vormax® Elongated Toilet

☐ 2882107

- **Wall-hung, back outlet gravity flush toilet configuration**
- VorMax flushing technology cleans two times better than conventional toilets**
- Combination bowl and tank, less seat
- Elongated siphon action bowl
- High efficiency toilet (HET) 1.28 gpf/4.8 Lpf
- Meets EPA WaterSense® criteria
- EverClean® Antimicrobial Surface included
- CleanCurve™ rim eliminates rim area where dirt and build-up hide
- Creates 50% less noise than pressure-assist technology toilets
- Consistently flushes and removes paper seat covers unlike many pressure-assist toilets which tend to rip and leave behind paper
- Meets all applicable drain line carry requirements and performs just as well as all pressure-assist HETs
- 16-1/2" (419 mm) rim height for accessible applications
- 2-1/16" (52 mm) trapway
- Dual injection flush valves
- Chrome trip lever included
- 10 year warranty (1 year commercial)
- Wall carrier supplied by others

☐ **2882108** Same as above except trip lever on right hand side

☐ **3447101** Elongated Bowl

☐ **4385A107** HET Tank

Nominal Dimensions:

29-1/2" x 17-13/16" x 32-13/16"
(750 x 453 x 833 mm)

Fixture only, seat, supply and wall carrier sold separately

Alternative Tank Configuration Available:

- ☐ **4385A108** Tank complete with trip lever located on right side
- ☐ **4385A167** Left hand trip lever tank with tank cover lock device.

Compliance Certifications -

Meets or Exceeds the Following Specifications:

- ASME A112.19.2/CSA B45.1 for Vitreous China Fixtures
- US EPA WaterSense® Specification for HETs

*Glenwall 1000g MaP score due 2019

** Source: Test Report No. 109-141486-002, comparing VorMax against conventional under-the-rim-water-dispersal toilets from major retailers.

† MaP testing performed by IAPMO R&T Lab. MaP report conducted by Gauley Associates Ltd. and Koeller and Company.



2882107 Combo with Seat 5055A65C



2882107 Combo with Seat 5901100

SEE REVERSE FOR ROUGHING-IN DIMENSIONS
AND PRODUCT SPECIFICATIONS

To Be Specified:

- ☐ Color: ☐ White
- ☐ Seat: #5055A65C Elongated Slow Close solid plastic seat and cover or #5901100 Elongated heavy-duty open front seat less cover
- ☐ Supply with stop:



When installed so top of seat is 432 to 483mm (17" to 19") from the finished floor.
MEETS THE AMERICANS WITH DISABILITIES ACT GUIDELINES AND ANSI A117.1 REQUIREMENTS FOR ACCESSIBLE AND USEABLE BUILDING FACILITIES-CHECK LOCAL CODES.



ENVIRONMENTAL
PRODUCT
DECLARATION




EVERCLEAN®



EPA
WATERSENSE®
CERTIFIED



WATER
EFFICIENT

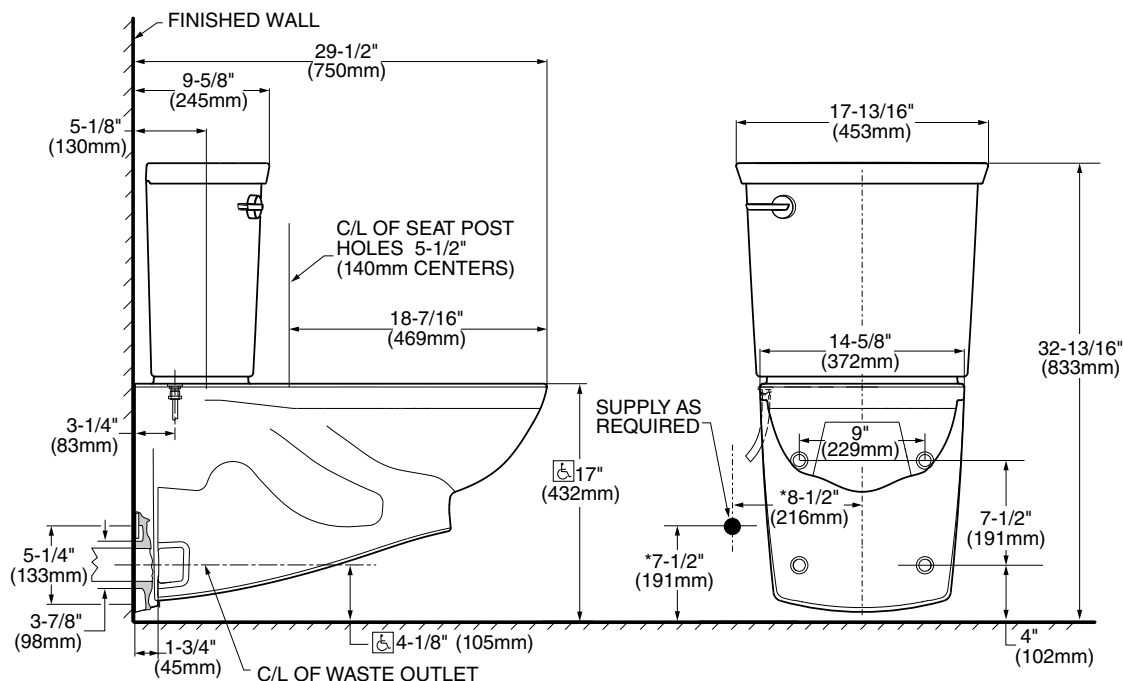

NOTES:

WASTE OUTLET SEAL RING MUST BE NEOPRENE OR GRAPHITE-FELT (WAX RING NOT RECOMMENDED)

SUGGEST 1/16" CLEARANCE BETWEEN FACE AT WALL AND BACK OF BOWL.

CARRIER FITTING TO BE FURNISHED BY OTHERS.

PROVIDE SUITABLE REINFORCEMENT FOR ALL SUPPORTS.

SUPPLY NOT INCLUDED WITH FIXTURE AND MUST BE ORDERED SEPARATELY.

* DIMENSION SHOWN FOR LOCATION OF SUPPLY IS SUGGESTED.

FOR ADDITIONAL INFORMATION REFER TO INSTALLATION INSTRUCTIONS SUPPLIED.

IMPORTANT: Dimensions of fixtures are nominal and may vary within the range of tolerances established by ANSI Standard A112.19.2. These measurements are subject to change or cancellation. No responsibility is assumed for use of superseded or voided pages.