


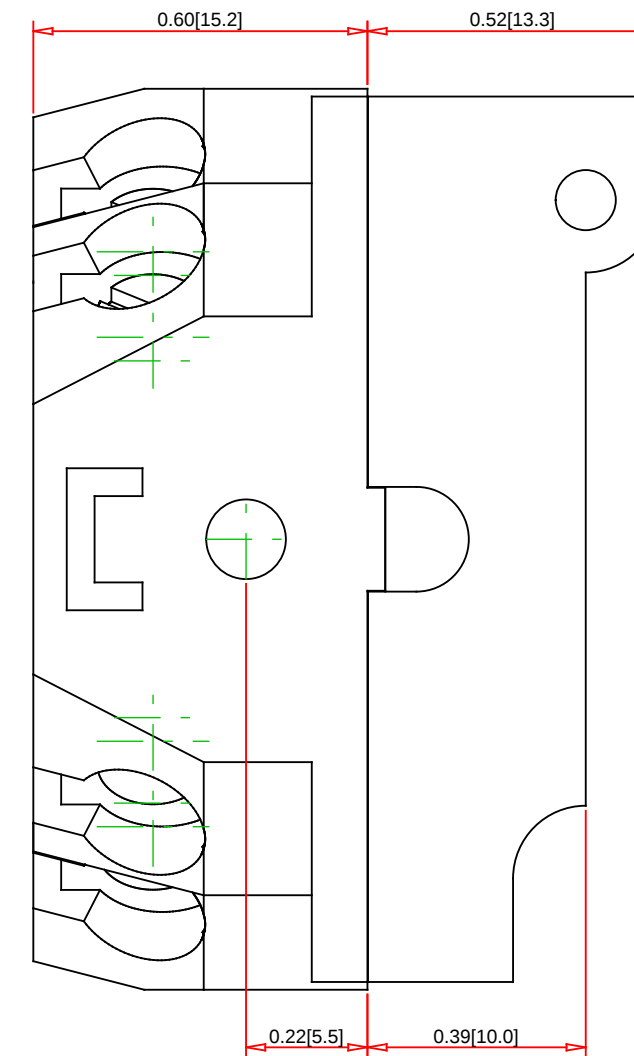

Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

9001KA1



Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 877 342 5173
Email: CCC@us.schneider-electric.com

Technical Information:

UL File: E78403 CCN NKCR
CSA File: LR24590 Class 3211-03
CE Marked: Yes
RoHS compliant: Yes
NEMA / IP Rating: IP20
Max. Voltage Rating: 600V

Description:

Ampere Rating: 10A
Contact Configuration: 1 NO - 1 NC
Contact Type: Standard (Fingersafe)
Terminal Type: Screw Clamp

Specification: