




Personalize Your Lockout Procedures by Providing a Visual Representation of the Authorized Employee

Customize with
worker name,
department,
and photo
for employee
identification

Clear adhesive
overlay allows
tags to be
personalized
on-site

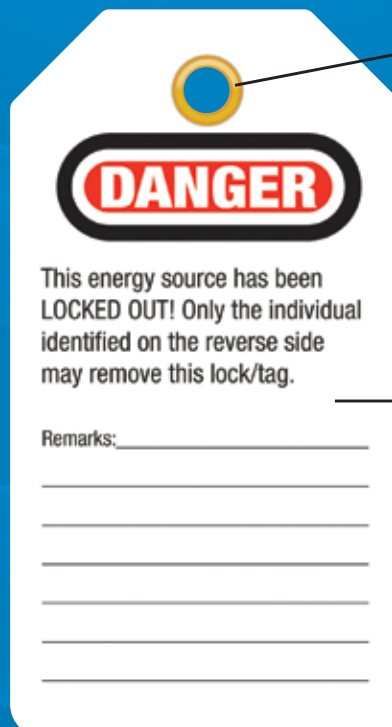

3/8 in. (9.5mm)
grommet and tag
withstand 50 lbs.
(22.7kg.) pull force

Tags are available
in English, French,
Spanish, and
bilingual versions

Product Numbers	S4801: English S4801LESLEN: Bilingual English/Spanish S4801LFRELEN: Bilingual English/French S4800LEN: English with European Danger Symbol S4800LES: Spanish with European Danger Symbol S4800LFR: French with European Danger Symbol S4802LEN: English with U.K. Prohibition Symbol
Description	Self-laminating photo ID safety lockout tags
Product Dimensions	3.2 in. W x 5.8 in. H (81.3mm W x 147.3mm H)
Weight	0.2 lbs. (0.09 kg.) per bag of tags
Material Composition	Polypropylene with PVC laminate overlay
Color	White with color graphics and clear overlay
Operating Temperature Range	-40F to 200F (-40C to 93.3C)
Pull Force	Tag, cable tie, and grommet withstand 50 lbs. (22.7 kg.) pull force
Chemical Resistance	Resistant to common industrial chemicals including: Isopropyl Alcohol, Methanol, Mineral Spirits, Kerosene, Toluene, Sodium Hydroxide*, Sodium Hypochlorite*, Sulfuric Acid*, Hydrochloric Acid* *Partially diluted
Compliance	Reach, Prop65
UPCs	S4801: 071649189180 S4801LESLEN: 071649189203 S4801LFRELEN: 071649189197 S4800LEN: 071649189234 S4800LES: 071649189227 S4800LFR: 071649189210 S4802LEN: 071649189234
Packaging	Commercial Bagged
Each Qty	Bag of 12 tags and 12 cable ties

Multiple Languages and Designs Available

S4801



S4801LESLEN



S4801LFRELEN



S4800LEN



S4800LES



S4800LFR



S4802LEN

