


9080GT6

Terminal block, Linergy, transient voltage suppressor, natural colored block, 120 VAC

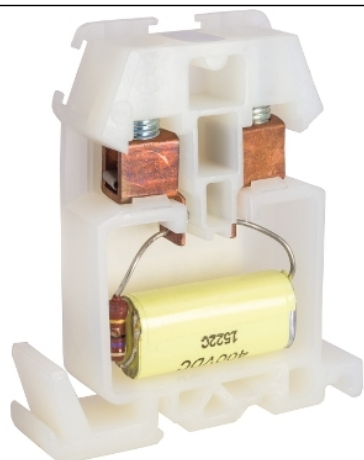

Main

Range of product	9080G
Product Type	Terminal block
Localisation on Device	Transient voltage suppressor
Color	Natural
Quantity	Set of 5

Complementary

Voltage Rating	120 V AC
Wire Size	AWG 18...AWG 10 copper
Mounting Type	9080GH track 35 mm DIN rail
Certifications	UL recognized E60616 CCN XCFR2 CSA file 62144 class 6228 01 CE
Protection Type	Fingersafe DIN 57470
Electrical Connection	Copper box lugs
Material	Nylon block
Ambient air temperature for operation	-40...257 °F (-40...125 °C)
Electrical Connrection Tightening Torque	Lug copper 18...20 lbf.in (2.03...2.26 N.m) : AWG 18...AWG 10 copper)
Height	2.55 in (64.77 mm)
Width	2.16 in (54.86 mm)
Depth	0.5 in (12.70 mm)
Density	24 per foot
Compatible End Barrier	GT6B

Ordering and shipping details

Category	21702 - 9080 G (NOT GCB)
Discount Schedule	CP5
GTIN	00785901652441
Nbr. of units in pkg.	1
Package weight(Lbs)	0.06 lb(US) (0.03 kg)
Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	0.50 in (1.27 cm)
Package 1 width	2.40 in (6.096 cm)
Package 1 Length	2.20 in (5.588 cm)
Unit Type of Package 2	CAR
Number of Units in Package 2	5
Package 2 Weight	5.60 oz (158.757 g)

Package 2 Height	2.50 in (6.35 cm)
Package 2 width	2.50 in (6.35 cm)
Package 2 Length	3.30 in (8.382 cm)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
PVC free	Yes

Contractual warranty

Warranty	18 months
----------	-----------