


Intense IR HD-TVI 1080p 2MP Indoor/Outdoor Dome/Turret Camera

HT6041T 3.6mm fixed lens, dark grey housing

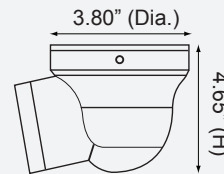

Features

- Full HD resolution over coax (HD-TVI)
- Supports up to Full HD 1080p @ 30fps
- True WDR operation
- Intense IR function – no saturation, IR intensity adapts to subject to provide vivid image
- True day/night operation – mechanical IR cut filter
- Heater circuitry and anti-moisture glass reduce fog or condensation under any weather condition
- 3-axis for wall and ceiling mounting
- Full OSD operation through on-board control and UTC (up the coax)
- 12VDC & 24VAC dual voltage operation
- Vandal / tamper resistant
- IP67 compliant
- 5 year warranty

Camera Specifications

Image Sensor	1/3" Sony Exmor CMOS, 2.0MP
Minimum Illumination.....	0.001 lux
Effective Pixels	1984 (H) x 1105 (V)
Total Pixels	2000 (H) x 1121 (V)
Scanning System.....	Progressive
IR Range	80 ft. (depending on scene reflection)
Intense IR	0 – 20 (adjustable)
S/N Ratio	More than 50dB
Output Resolution.....	1920x1080 @ 30fps / 1280x720 @ 60fps
Video Output.....	1.0Vp-p / 75 Ohms
Electronic Shutter	Auto / Manual (1/30 – 1/30,000 sec.) / Flicker
WDR.....	On (Low / Middle / High) / Off
Day / Night.....	Auto / Color / BW / External
White Balance	Auto / AWB / AWC-Set / Manual
Brightness.....	0 – 20 (adjustable)
AGC.....	0 – 20 (adjustable)
Sense-up	2x – 32x (adjustable)
Backlight.....	BLC / HSBLC
Motion Detection.....	On / Off (4 zones)
Privacy Masking	On / Off (16 zones)

Camera Specifications (continued)

Mirror	On / Off
V-Flip	On / Off
Sharpness	0 – 20 (adjustable)
Lens Shading.....	On / Off
DNR.....	Off / Low / Middle / High
Test Monitor Output	CVBS
Communication.....	UTC (up the coax)
Operating & Unit Specifications	
Power	12VDC / 24VAC dual voltage (power supply not included)
Power Consumption	12VDC, 580mA max. / 24VAC, 218mA max.
Operating Temperature....	-4°F – 140°F
Operating Humidity.....	20% – 95% RH
Unit Dimensions	4.65" (H) x 3.8" (Dia.)
Unit Weight.....	4.4 lbs.
Certifications.....	FCC, RoHS

Optional Accessories



INTPM
Pendant Mount
(use with 60PLATE
and CVCJBD)



INTWM
Wall Mount
(use with 60PLATE
and CVCJBD)



CVCJBD
Dome Camera
Junction Box
(use with 60PLATE)



60PLATE
Adaptor Plate



PSW4
24VAC
Power Supply



PSW5
12VDC
Power Supply



Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation. Spec Rev. 3/16/15