



## Main

Product or component type	Circuit breaker
---------------------------	-----------------

## Complementary

Line Rated Current	600 A
Number of Poles	3P
Breaking capacity code	J
Magnetic Tripping Current	1200...6000 A
Electrical connection	Lugs load Terminal nut line
Terminal identifier	AL800M23K
Tightening torque	442.54 lbf.in (50 N.m) 0.15...0.37 in <sup>2</sup> (95...240 mm <sup>2</sup> ) (AWG 3/0...500 kcmil)
Height	12.86 in (326.6 mm)
Width	0.32 in (8.06 mm)
Depth	8.27 in (210 mm)
Continuous current rating	80 %

## Ordering and shipping details


Category	01205-MG, MJ UNIT MOUNT BREAKER
Discount Schedule	DE2
Package weight(Lbs)	29.00 lb(US) (13.154 kg)
Returnability	Yes
Country of origin	US

## Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: DINP, which is known to the State of California to cause cancer, and DIDP, which is known to the State of California to cause birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
RECh Regulation	<a href="#">RECh Declaration</a>
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>

Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	<a href="#">End Of Life Information</a>
PVC free	Yes
<b>Contractual warranty</b>	
Warranty	18 months

Approximate Dimensions

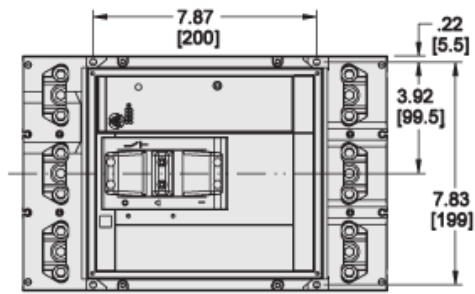

in.  
[mm]

