


# CONVERSIONCALC PLUS™


ULTIMATE PROFESSIONAL CONVERSION CALCULATOR

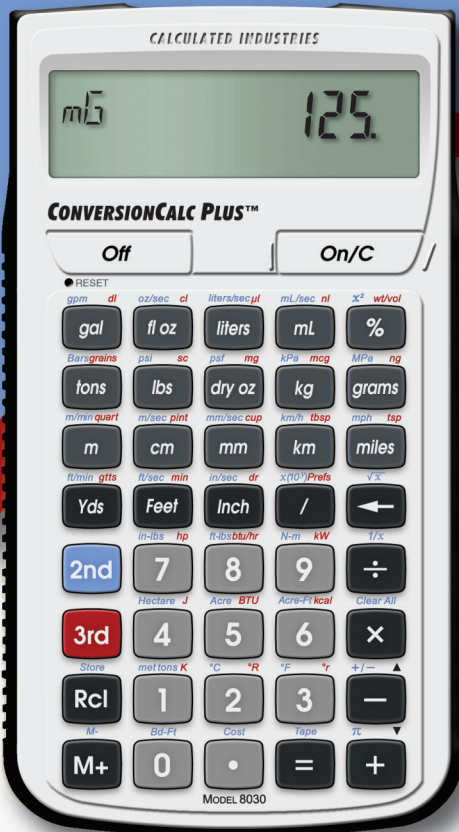


Model 8030

## Precise. Fast. Easy to Use. Convenient.

 
An easy-to-use and powerful handheld calculator that provides more than 500 conversion combinations using 70 built-in U.S. Standard, Metric and other units of measure. Work in and convert between linear, area and volume units, plus weights, temperatures, velocity and more! Don't waste time looking up tables in books and online.



 
**Volumes:** Convert gallons or ounces to drams, microliters, nanoliters, and more



 **Weights:** Convert tons, metric tons or pounds to grams, nanograms, grains, scruples, and more



 **Pressure:** Convert pounds per square foot or square inch to bars, kilopascals or megapascals



**Torque:** Convert foot-pounds to inch-pounds or Newton-meters

## CONVERSIONCALC PLUS™ is the choice for:



Engineers



Lab Technicians



Pharmacists

### The professional choice for:

- Engineers
- Lab Technicians
- Scientists
- Pharmacists
- Nutritionists
- Specifiers
- Importers/Exporters
- Purchasing Agents

### Product Specifications

**Size:** 5.7" x 3.0" x 0.65" (145 mm x 76 mm x 17 mm)

**Weight:** 4.15 oz. (118 gm) Includes Slide Cover and Pocket Reference Guide

**Power:** One 3-volt (CR2016) Long-life Battery

**Display:** 14 Digits (8 normal, 6 fractions) with Full Annunciators

**LCD Dimensions:** 0.73" x 2.56" (19 mm x 65 mm)

**Accuracy:** 12 Digit Internal Accuracy

**Maximum Display:** Up to 9999999.99

**Included with Every ConversionCalc Plus:** Protective Slide Cover; Long-life Battery (One CR2016); Quick Reference and Pocket Reference Guides.

**Full One-Year Limited Warranty**



4840 Hytech Drive  
Carson City, NV 89706  
1-800-854-8075

Visit our website at:  
[www.calculated.com](http://www.calculated.com)

# CONVERSIONCALC PLUS™

ULTIMATE PROFESSIONAL CONVERSION CALCULATOR

**CONVERSIONCALC PLUS** is an easy-to-use and powerful handheld calculator that provides more than 500 conversion combinations using 70 built-in U.S. Standard, Metric and other units of measure. You can work in and convert between linear, area and volume units, plus weights, temperatures, velocity without cumbersome formulas or tedious table look-ups.

## Flow Rate —

*gallons per minute,  
ounces per second,  
liters per second,  
milliliters per second*

## Weight —


*pounds,  
tons, dry ounces, metric  
tons, grams, milligrams,  
micrograms, nanograms,  
grains, scruples*

## Linear, Area and Volume Dimensions —

*Feet-inch-fractions and  
metric, plus board feet,  
acre feet, gallons,  
fluid ounces, quarts, pints,  
tablespoons, teaspoons,  
drams, minims; liters,  
milliliters, deciliters,  
centiliters, microliters,  
nanoliters, drops (gtts)*

## Temperature —

*Fahrenheit, Celsius,  
Rankine, Réaumur,  
Kelvin*

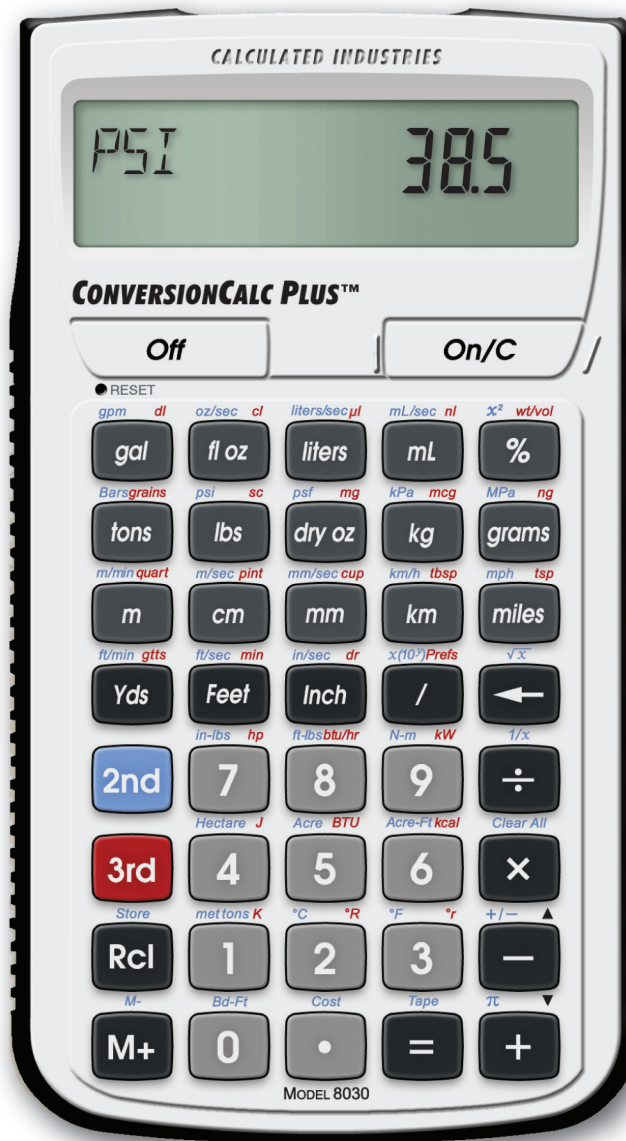

## Weight per Volume —

*from metric tons per  
cubic meter to grains  
per cubic inch and  
everything in between*

## Pressure —

*pounds per square  
inch, pounds per  
square foot, bars,  
kilopascals,  
megapascals*

## Torque —

*pound-inch,  
pound-foot,  
Newton-meters*

## Energy —

*Joules,  
British thermal units,  
kilocalories*

## Power —

*horsepower,  
Btu per hour, kilowatts*

## Velocity —

*feet per minute, inches  
per second, feet per  
second, miles per hour,  
meters per second,  
millimeters per second,  
kilometers per hour*

MODEL 8030 - Actual Size

**Health Care Professionals • Scientists • Pharmacists • Nutritionists  
Lab Techs • Engineers • Specifiers • Importers/Exporters**