

Catalog Number
Notes
Type

FEATURES & SPECIFICATIONS

INTENDED USE

Utility wall-, ceiling- or pendant-mounted fixtures for entrances, hallways, closets, tunnels or other utility applications. Incandescent, fluorescent, metal halide or high pressure sodium sources are available.

CONSTRUCTION

Rugged die-cast aluminum housing with heavy-duty glass globe. 3/4" threaded knockouts allow for side or top conduit entry. Gray finished.

Designed for easy installation and maintenance.

Prismatic globe for even distribution.

Junction box included

LISTINGS

Listed and labeled to UL standards for wet locations.

Listed and labled to CSA standards.

WARRANTY

2-year limited warranty. Complete warranty terms located at:

www.acuitybrands.com/support/warranty/terms-and-conditions

Note: Actual performance may differ as a result of end-user environment and application.

Specifications subject to change without notice.

Specifications

All dimensions are inches (centimeters) unless otherwise indicated.

Ceiling


VC150I



Height: 9 (22.9)
Width: 4-1/2 (11.4)

Wall

VW150I

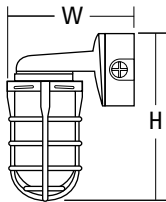

Height: 10 (25.4)
Width: 7-1/4 (18.4)

Utility Vapor Tights



VC



VW

ORDERING INFORMATION

Catalog Number	UPS	Description	Lamp Wattage	Source	Lamp Voltage	Lamp Included	Pallet (lbs)	Standard Carton Qty	Qty
VC150I M12	745973817704	Ceiling mount	150	Incandescent	120	N	2	288	12
VW150IM12	745973817681	Wall Mount	150	Incandescent	120	N	2	192	12