



Main

Range	Linergy
Product name	FT
Device short name	GV2G
Product or component type	Comb busbar
Accessory / separate part category	Connection accessory
Poles description	3P
Range compatibility	TeSys D TeSys GV2 TeSys K TeSys U
Number of tap-offs	2
[I _{th}] conventional free air thermal current	63 A
Connection pitch	2.13 in (54 mm)

Complementary

Mounting location	On terminal
[Ui] rated insulation voltage	690 V
Length	3.86 in (98 mm)
Net Weight	0.08 lb(US) (0.038 kg)

Ordering and shipping details

Category	22367 - MANUAL STR PROTECTOR - GV2
Discount Schedule	I11
GTIN	00785901490081
Nbr. of units in pkg.	1
Package weight(Lbs)	0.09 lb(US) (0.04 kg)
Returnability	Yes
Country of origin	RO

Packing Units

Package 1 Height	0.110 dm
Package 1 width	1.050 dm
Package 1 Length	0.350 dm

Offer Sustainability


Sustainable offer status	Green Premium product
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile

Contractual warranty


Warranty

18 months

Sets of Busbars GV2G... with Terminal Block GV1G09

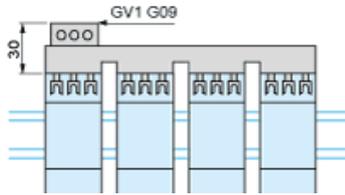

Sets of Busbars GV2G245, GV2G254, GV2GR272

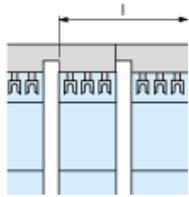

	l
GV2G245 (2 x 45 mm)	89
GV2G254 (2 x 54 mm)	98
GV2G272 (2 x 72 mm)	116