



INSTALLATION INSTRUCTIONS

COSMETIC SERIES— SURFACE MOUNTED

Product Information

Cosmetic Box with Mirror Features:

- Polished Stainless Steel
- PVC Track System
- White Baked Enamel Interior
- 3/16" First Quality Plate Glass Sliding Doors



** Professional Installation is recommended to insure proper installation.

** Please do not stand your medicine cabinet on end while unboxing. Lie the cabinet down mirror side up prior to installation. Set on a clean surface, like a towel or carpet to avoid damage.

** Prior to discarding the packaging, locate shelves, door hardware, and screws where applicable.

Installation Steps

1. Mark the desired position "X". Mount the hangers on wall using the flat head wood screws provided in the fixing pack. (Figure 1)
NOTE: If unable to screw into studs, use toggle bolts or other suitable fasteners.
2. Position the cabinet above the hanger and holding top flat against the wall, slide the cabinet down until securely seated in the hangers. (Figure 2)
3. Attach the back of the cabinet to the wall with the round head screws provided. As indicated at "Y". (Figure 1)
NOTE: If unable to screw into studs, use toggle bolts or other suitable fasteners.
4. Assemble door pull to door as follows:
Step 1: Place door on a flat surface with the mirror side or plastic side up.
Step 2: Remove the paper back from the pull and press into place. (Figure 3)
5. Install sliding doors in cabinet by lifting into upper channel and dropping them down into lower channel.
NOTE: Insert right hand door in the rear channel first .

NOTICE:

1. Gently close the cabinet door to avoid potential injuries and damage. Damaged glass should be replaced right away.
2. The cabinet must be installed onto a solid wall. (Thinner wood siding wall and hollow wall are not applicable)

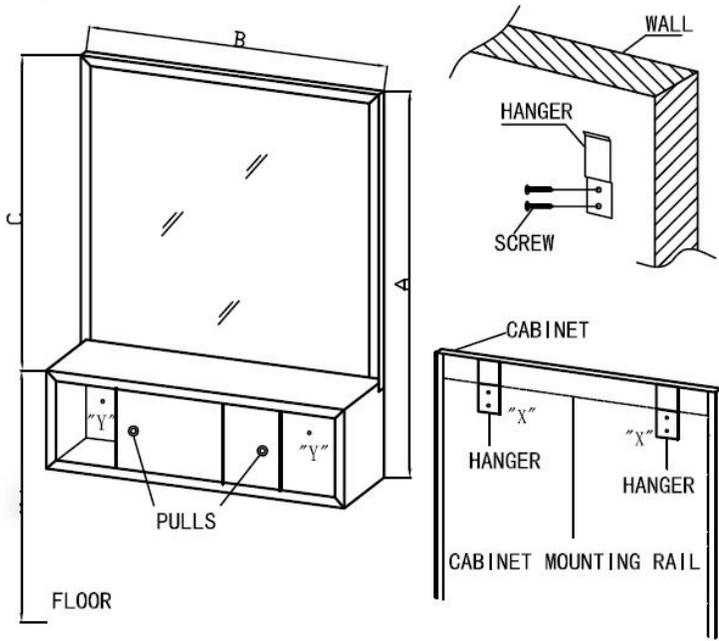


Fig. 1

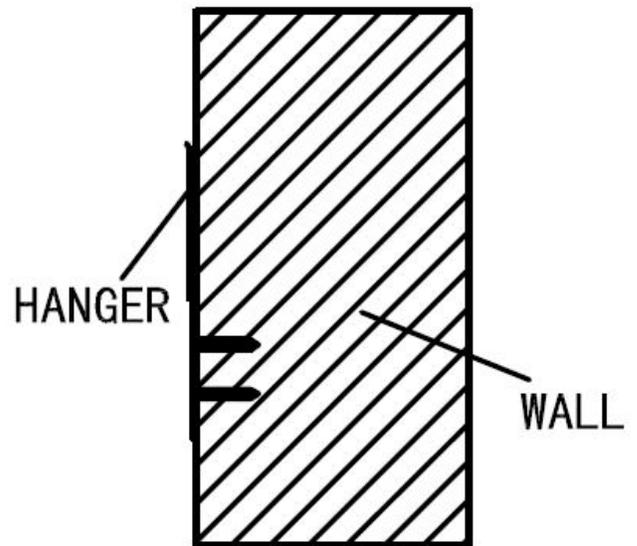


Fig. 2

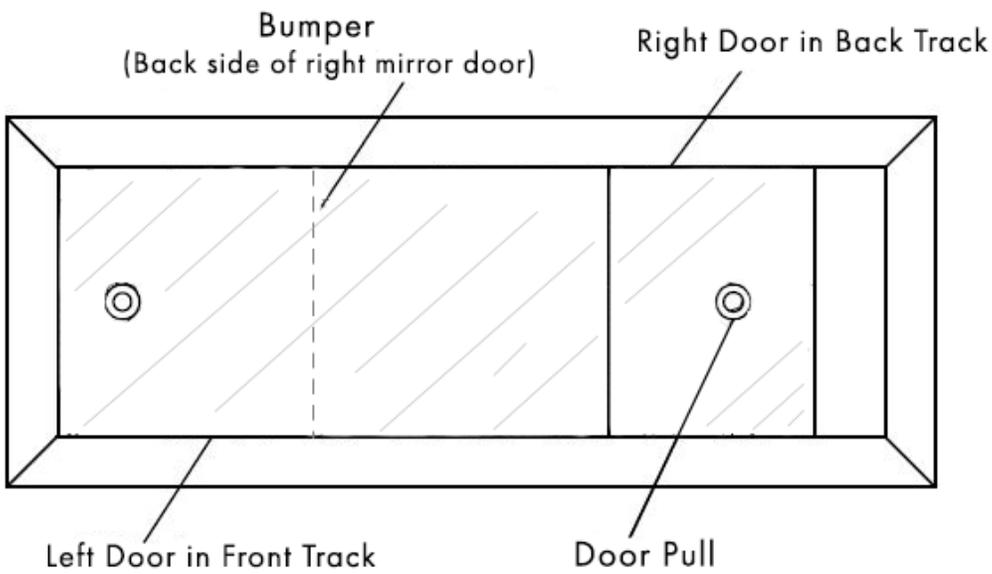


Fig. 3