


DC POWER SUPPLY: 24 VAC TO 1.5 - 14 VDC

PSM20A12DAS

4.00" & 2.75" Track Mount Isolated Linear DC Power Supply, 24 Vac to 1.5-14Vdc, 300 mA Adjustable Output

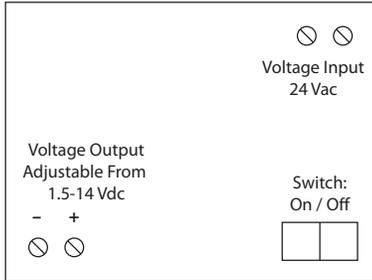

SPECIFICATIONS

- Voltage Input:** 24 Vac
- Voltage Output:** 1.5 - 14 Vdc Isolated
- Frequency:** 50/60 Hz
- Overload Protection:** Electrical and Thermal, Auto-Reset
- Operating Temperature:** -30 to 140° F
- Humidity Range:** 5 to 95% (noncondensing)
- Power Status:** LED On = Activated
- Dimensions:** 1.625" x 2.750" x 4.000"
- Track Mount:** 4.000" and 2.750"
MT212-4 Mounting Track Supplied
- ON/OFF Switch:** 2 Position
- Approvals:** UL916, C-UL, CE, RoHS

Output Current Ratings:
300 mA @ 12 Vdc

Input Current Rating:
950 mA Maximum

Percent Ripple:
0.0016%, 12 Vdc @ 300 mA

Regulation:
Load: 0.04% No Load to Full Load
Line: 0.0080 mV/V