


30 AMP TRACK MOUNT CONTROL RELAY

RIBM243PN

4.00" Track Mount Relay 30 Amp 3PDT with 24 Vac/dc Coil

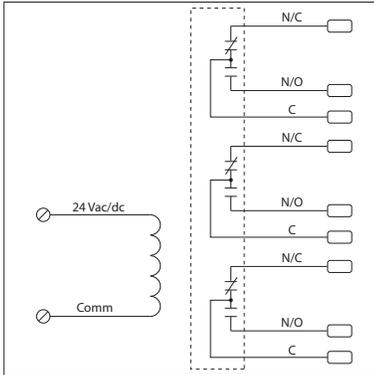

SPECIFICATIONS

- # Relays & Contact Type: One (1) 3PDT Continuous Duty Coil
- Expected Relay Life: 10 million cycles minimum mechanical
- Operating Temperature: -30 to 140° F
- Humidity Range: 5 to 95% (noncondensing)
- Operate Time: 20ms
- Relay Status: LED On = Activated
- Dimensions: 2.375" x 4.000" x 1.750"
- Track Mount: 4.000"
- MT4 Mounting Track Sold Separately
- Approvals: UL Component Recognized, UL916
C-UL, CE, RoHS
- Gold Flash: No
- Override Switch: No

- Contact Ratings:**
- | | |
|----------------------------------|----------------------------|
| 30 Amp General Use @ 300 Vac | Heavy Pilot Duty @ 600 Vac |
| 30 Amp Resistive @ 28 Vdc | 770 VA @ 120 Vac, 1 Phase |
| 20 Amp Ballast @ 277-480 Vac | 1158 VA @ 240 Vac, 1 Phase |
| Not rated for Electronic Ballast | 1110 VA @ 277 Vac, 1 Phase |
| 15 Amp Resistive @ 600 Vac | 1640 VA @ 480 Vac, 1 Phase |
| 7.5 HP @ 480 Vac, 3 Phase | 1466 VA @ 240 Vac, 3 Phase |
| 5 HP @ 240 Vac, 3 Phase | 2122 VA @ 480 Vac, 3 Phase |
| 3 HP @ 480-600 Vac, 1 Phase | |
| 2 HP @ 240-277 Vac, 1 Phase | |
| 1 HP @ 120 Vac, 1 Phase | |

- Coil Current:**
- 190 mA @ 24 Vac
 - 140 mA @ 30 Vdc
- Coil Voltage Input:**
- 24 Vac/dc; 50-60 Hz
 - Drop Out = 3 Vac / 3.8 Vdc
 - Pull In = 20 Vac / 22 Vdc