
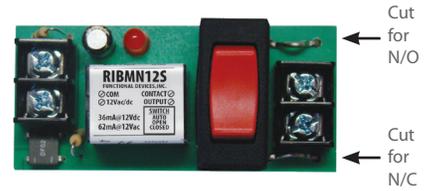


15 AMP TRACK MOUNT CONTROL RELAY

RIBMN12S

2.75" Track Mount Relay 15 Amp SPST

+ **Override** with 12 Vac/dc Coil

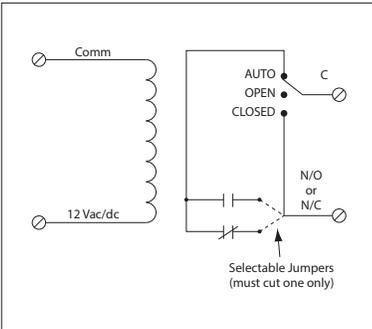

SPECIFICATIONS

- # Relays & Contact Type:** One (1) SPST Continuous Duty Coil
- Expected Relay Life:** 10 million cycles minimum mechanical
- Operating Temperature:** -30 to 140° F
- Humidity Range:** 5 to 95% (noncondensing)
- Operate Time:** 6ms
- Relay Status:** LED On = Activated
- Dimensions:** 1.250" x 2.750" x 1.750"
- Track Mount:** 2.750"
- Approvals:** UL Listed, UL916, UL864, C-UL California State Fire Marshal, CE, RoHS
- Gold Flash:** No
- Override Switch:** Yes

MT212 Mounting Track Sold Separately

- Contact Ratings:**
- 15 Amp General Use @ 125 Vac
- 10 Amp General Use @ 277 Vac
- 10 Amp Resistive @ 30 Vdc (N/O)
- 7 Amp Resistive @ 30 Vdc (N/C)
- 1/2 HP @ 125 Vac
- 1 HP @ 250 Vac
- 1/4 HP @ 277 Vac
- C300 Pilot Duty

- Coil Current:**
- 53 mA @ 10 Vac
- 62 mA @ 12 Vac
- 29 mA @ 11 Vdc
- 35 mA @ 12 Vdc

- Coil Voltage Input:**
- 12 Vac/dc ; 50-60 Hz
- Drop Out = 2 Vac / 2.5 Vdc
- Pull In = 9 Vac / 11 Vdc

Notes:

- Must cut appropriate jumper to select Normally Open or Normally Closed