


AC CURRENT SWITCH

RIBXJF

Enclosed Self-Powered Split Ring Remote
Fixed 3-150 Amp AC Sensor

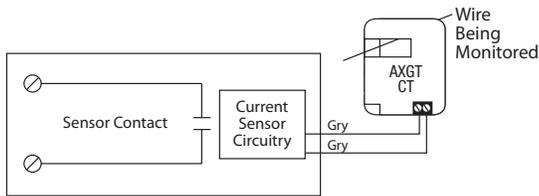

SPECIFICATIONS

FUNCTIONAL DEVICES CERTIFIED FOR USE WITH ECMs

- Operating Temperature:** -30 to 140° F
- Humidity Range:** 5 to 95% (noncondensing)
- Dimensions:** 4.00" x 4.00" x 1.80" with .50" NPT Nipple
- Remote Dimensions:** (Outside) 2.52" x 2.00", (Inside) .52" x .52"
- Wire Length:** 16", 600V Rated
- Approvals:** UL Listed, UL916, UL864, C-UL
California State Fire Marshal, CE, RoHS
- Housing Rating:** UL Accepted for Use in Plenum, NEMA 1

- Sensor Type:** External, with contact status
- Sensor Threshold:** Fixed, 3 Amps
- Sensor Range:** 3-150 Amps
- Max Sense Voltage:** 600 Vac
- Sensor Contact Status:** Current below threshold: Open / LED OFF
Current above threshold: Closed / LED ON

- Sensor Contact:**
- Solid State Contact
 - 30 Vac/dc, 4 Amp Max.
 - When sensor contact is off (open), leakage <30 uA @ 30Vac/dc
 - When sensor contact is on (closed), voltage drop < .3 Vac/dc @ .1 Amp
< 1.6 Vac/dc @ .4 Amp