

PORTAPUMP®

Convenient. Durable. Portable.



REMOVE WATER FROM UNWANTED
LOCATIONS QUICKLY AND EASILY
WITH THE PORTAPUMP



Plumbing Maintenance



Cemetery Maintenance



Golf Course Maintenance



Municipalities & Utilities



Landscaping & Irrigation



Construction

**WARREN
RUPP, INC.**

SANDPIPER®

PERFORMANCE & DIMENSIONS

MAX FLOW

• 43 GPM (163 LPM)

PORTING

• 1 1/2" NPT / BSP

CASING


• Aluminum

IMPELLER

• Cast Iron

MAX SOLIDS HANDLING

• .38"

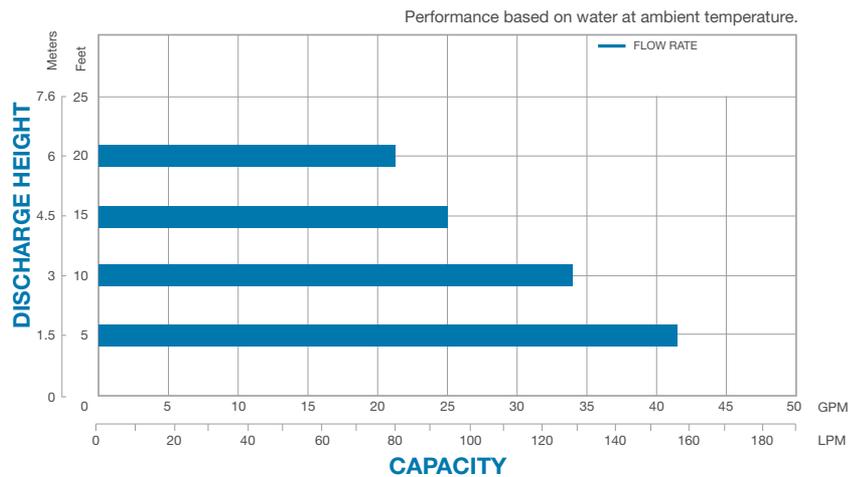

The SANDPIPER PortaPump® is a rugged, submersible, battery-powered pump that conveniently operates using any 12-volt car or truck battery.

The PortaPump comes equipped with 30' cables and battery clips. The unit is portable, weighing only 33 lbs (15 kg), and fits through openings as small as 10" (25cm).

Convenient

1/3-hp motor delivering up to 43 GPM (163 LPM) for rapid dewatering and instant prime

Portable

Unit weighs just 33 lbs (15 kg) and is available in a rugged carrying case

Long Lasting Performance

30-amp draw, for an average of one hour of operation without restarting the engine. (Times may vary)



SANDPIPER®

Warren Rupp, Inc.
A Unit of IDEX Corporation
800 North Main Street
Mansfield, OH 44902 USA

Phone: 419.524.8388
Fax: 419.522.7867
SANDPIPERPUMP.COM



©Copyright 2020 Warren Rupp, Inc. All Rights Reserved.

Visit www.sandpiperpump.com and click on "Find a distributor" to contact your local distributor to place your order