


HOM612L125ICU

Load center interior, Homeline, 1 phase, 6 spaces, 12 circuits, 125A convertible main lugs, NEMA1, special

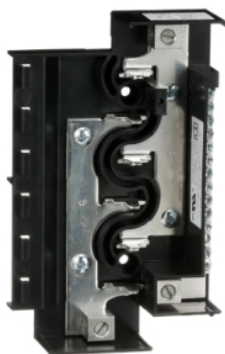

Main

Product Type	Load Center Interior Assembly
Marketing Trade Name	Homeline
Load Center Type	Main lugs
Rated Current	125 A
Number of Spaces	6
Maximum Number of Single Pole Circuits	12
Voltage Rating	120/240 V AC

Complementary

Wire Size	AWG 8...AWG 2/0 aluminium/copper
Tightening Torque	4.5 N.m, AWG 8 5 N.m, AWG 6...AWG 4 5.6 N.m, AWG 3...AWG 2

Environment

Ambient Air Temperature for Operation	23 °F (-5 °C) 104 °F (40 °C)
Product Certifications	UL Recognized

Ordering and shipping details

Category	00185-MISC. HOM LOAD CENTERS
Discount Schedule	DE3C
GTIN	00785901629719
Package weight(Lbs)	14.01 oz (397.165 g)
Returnability	No
Country of origin	MX

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
RECh Regulation	RECh Declaration
RECh free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty

18 months
