



### Main

Range of product	Altivar Lexium
Product or component type	EMC input filter
Range compatibility	Lexium 32 Lexium 52 Lexium 28 Altivar Machine ATV340
Product compatibility	LXM28A LXM32, three-phase, line current 14.6...18.1 A Variable speed drive ATV340 2.2 kW, 380...480 V Variable speed drive ATV340 3 kW, 380...480 V Variable speed drive ATV340 4 kW, 380...480 V Variable speed drive ATV340 5.5 kW, 380...480 V Variable speed drive ATV340 7.5 kW, 380...480 V
Product specific application	Radio interference input filter
Mounting location	At variable speed drive side
Phase	Three phase

### Complementary

Maximum cable distance between devices	65.62 Ft (20 m) IEC 61800-3 category C1 164.04 Ft (50 m) IEC 61800-3 category C2 328.08 ft (100 m) IEC 61800-3 category C3
Line Rated Current	25 A
Thermal losses	15.8 W
Network rated voltage	380...500 V
Tolerance	- 15...10 %
Net Weight	2.98 lb(US) (1.35 kg)
Emc filter compatibility	Type 023

### Ordering and shipping details

Category	22152 - ATV320/ATV312/ATV32 (.25 THRU 7.5HP)
Discount Schedule	CP4B
GTIN	00785901132738
Nbr. of units in pkg.	1
Package weight(Lbs)	3 lb(US) (1.36 kg)
Returnability	No
Country of origin	TH

### Packing Units

Unit Type of Package 1	PCE
Package 1 Height	2.44 in (6.2 cm)
Package 1 width	11.65 in (29.6 cm)
Package 1 Length	8.82 in (22.4 cm)
Unit Type of Package 2	S04
Number of Units in Package 2	11
Package 2 Weight	37.68 lb(US) (17.091 kg)
Package 2 Height	11.81 in (30 cm)
Package 2 width	15.75 in (40 cm)
Package 2 Length	23.62 in (60 cm)

Unit Type of Package 3	P06
Number of Units in Package 3	44
Package 3 Weight	176.55 lb(US) (80.08 kg)
Package 3 Height	30.31 in (77 cm)
Package 3 width	23.62 in (60 cm)
Package 3 Length	31.50 in (80 cm)


### Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>

### Contractual warranty

Warranty	18 months
----------	-----------

Additional EMC Input Filters

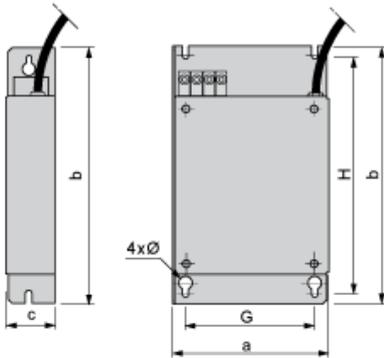

Dimensions in mm

a	b	c	G	H	Ø
140	235	50	120	215	4.5

Dimensions in in.


a	b	c	G	H	Ø
5.51	9.25	1.96	4.72	8.46	0.18

---


Mounting Recommendations

---

Mounting the Filter on the Side of the Drive

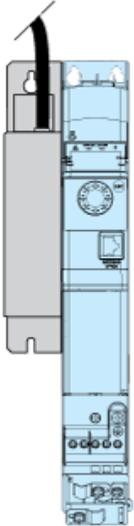

Recommended Schema

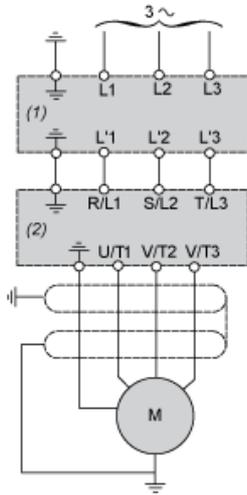

- (1) Filter
- (2) Drive