


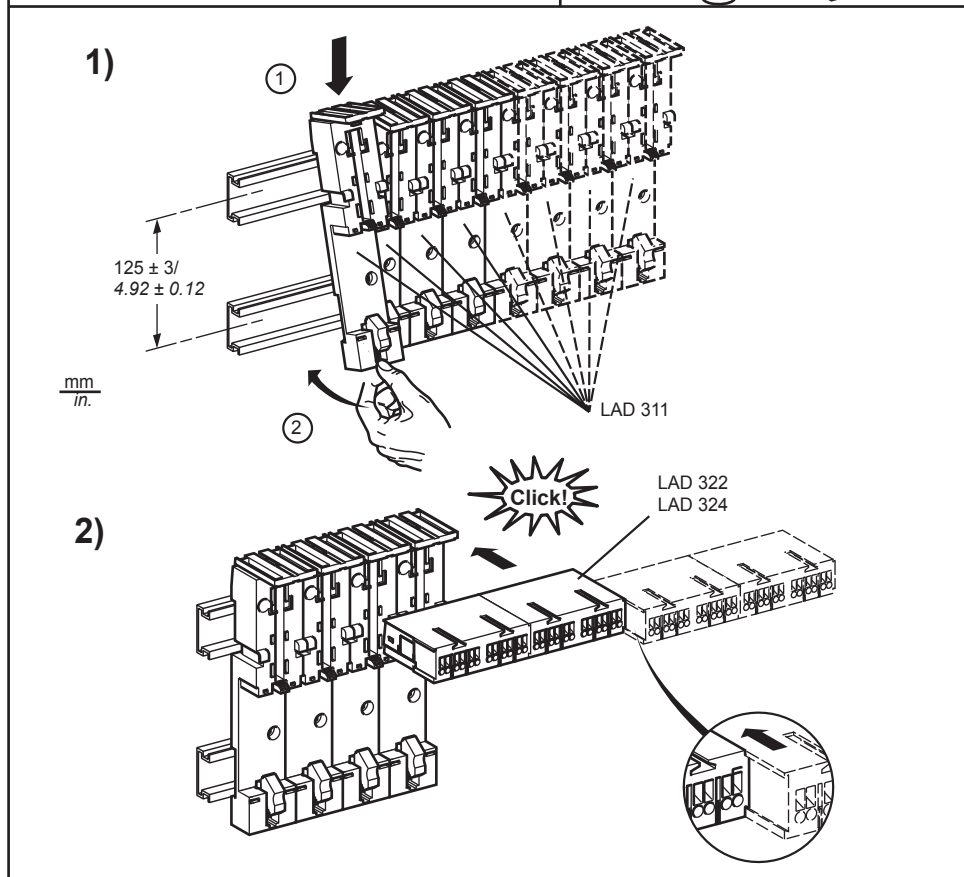


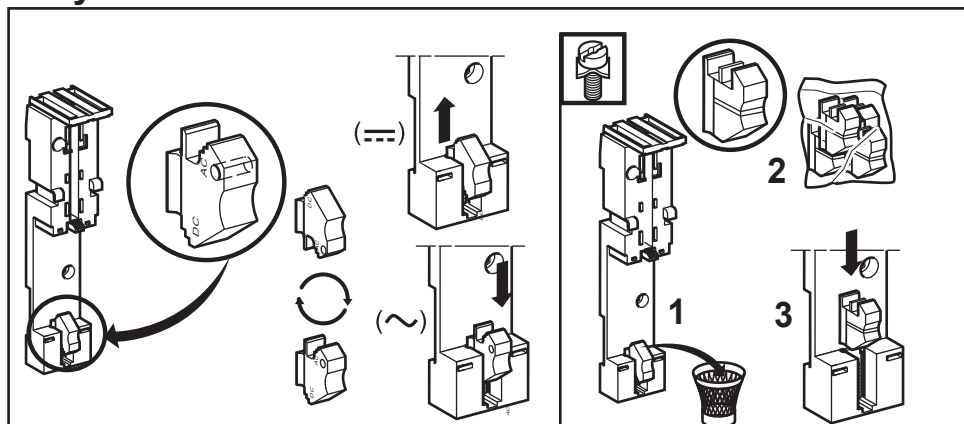


3)

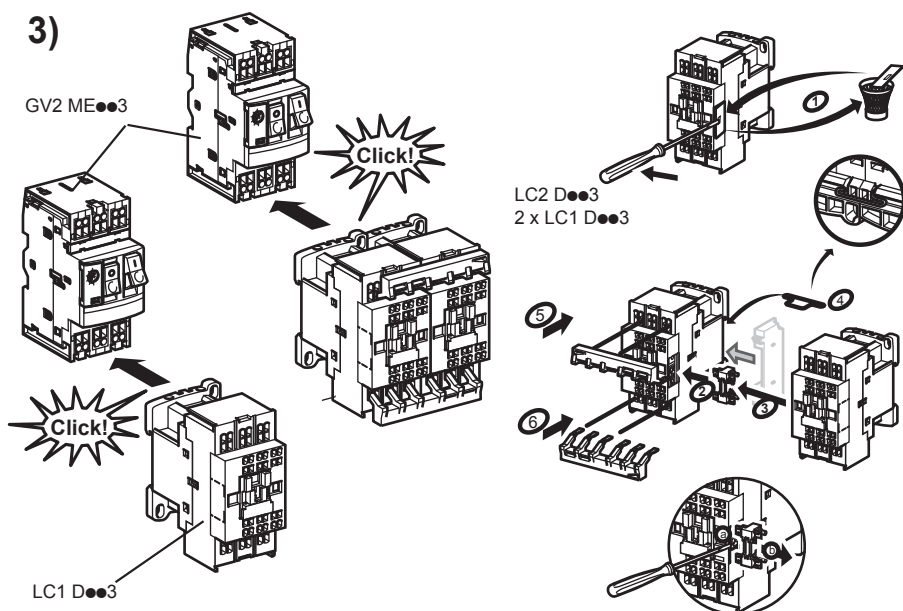


4)

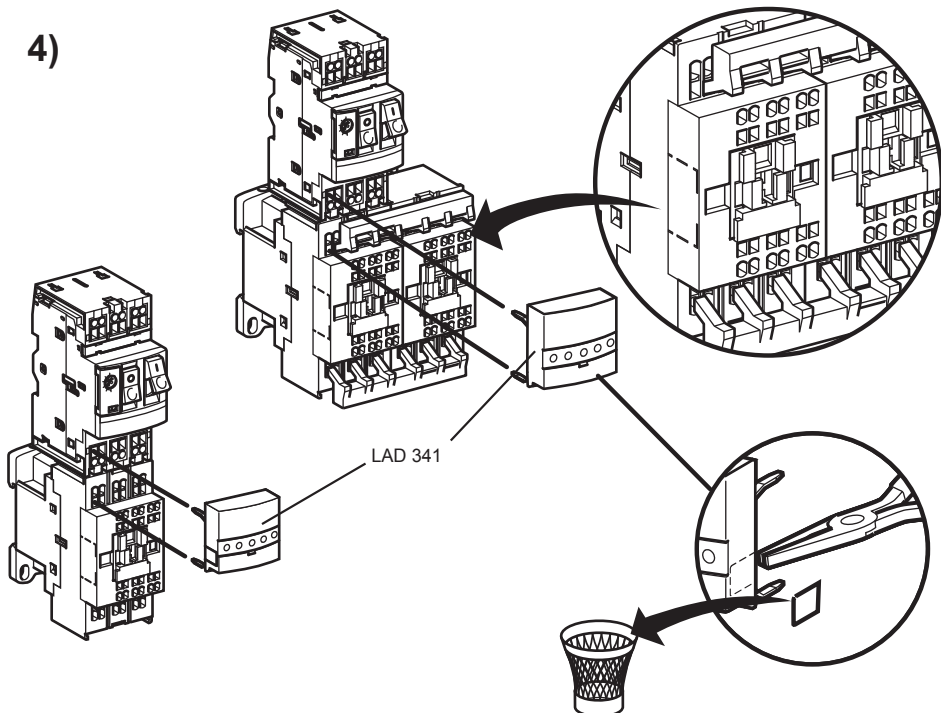

5)

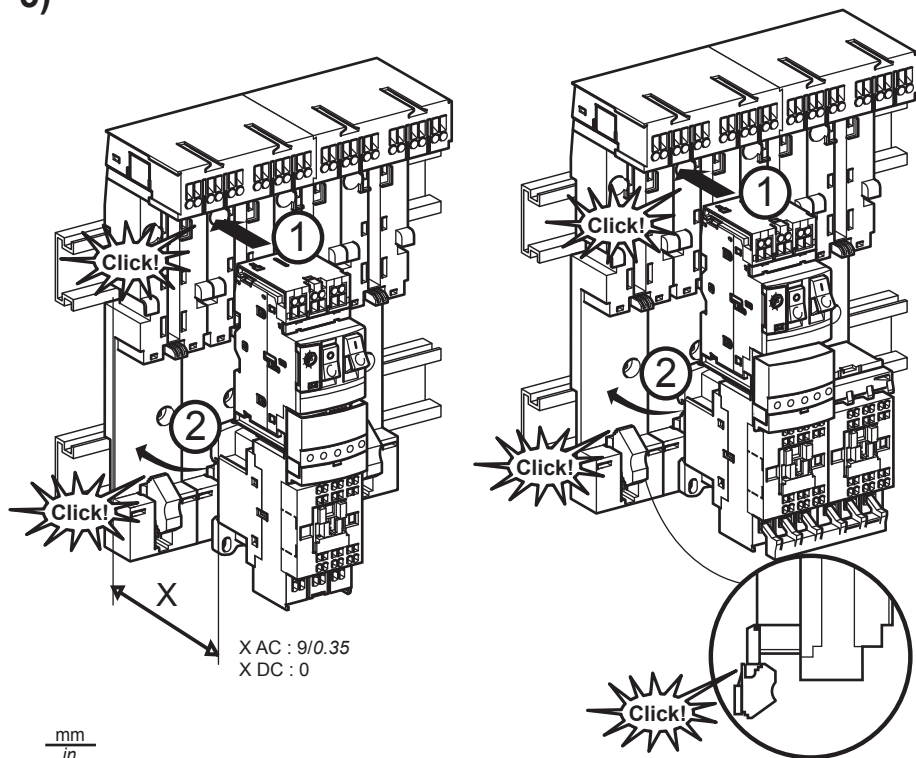


$\frac{\text{mm}}{\text{in.}}$

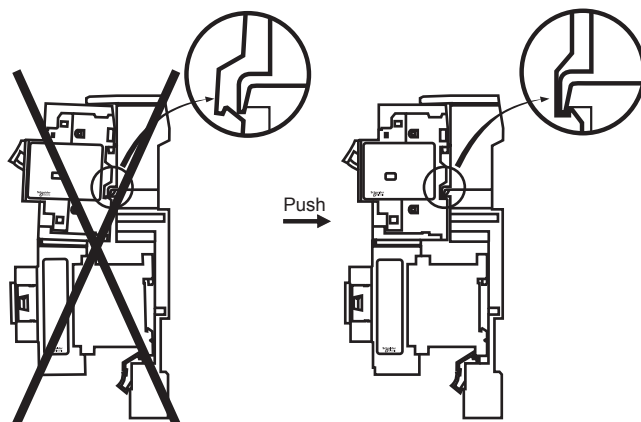


6)

$\leq 25 \text{ A} / 4 \text{ mm}^2$   
 $\leq 25 \text{ A} / \text{AWG10-18}$


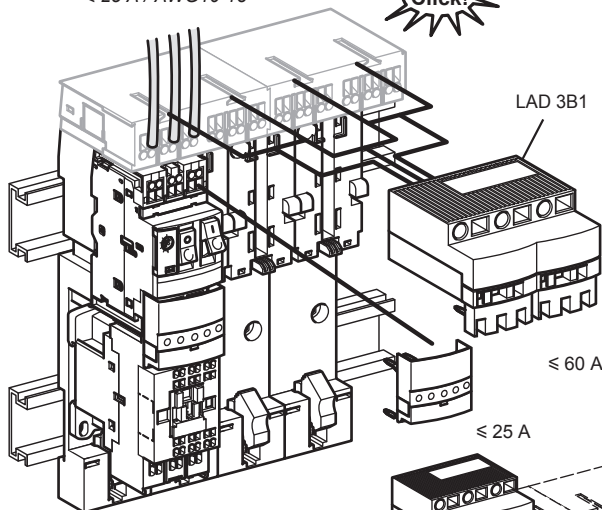


$\leq 60 \text{ A}$


$\leq 25 \text{ A}$

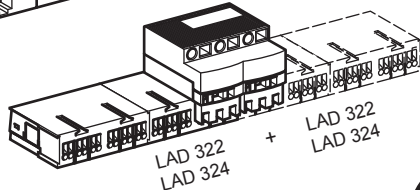

7)

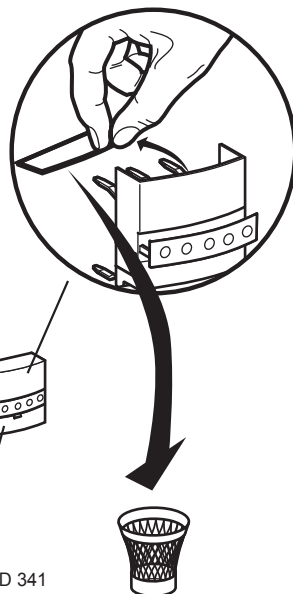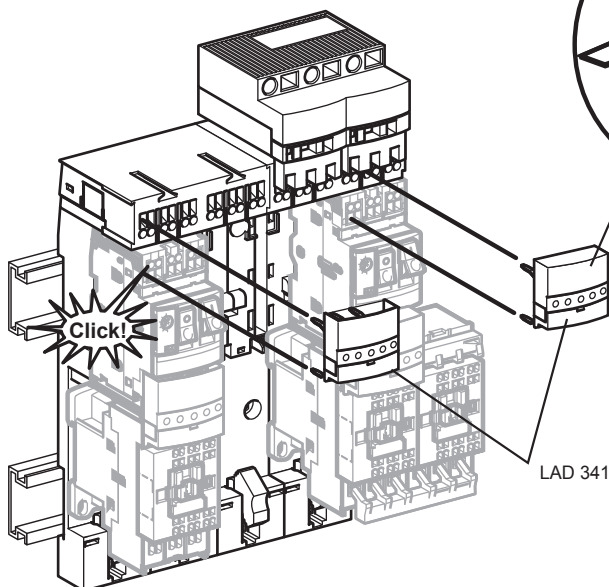


8)

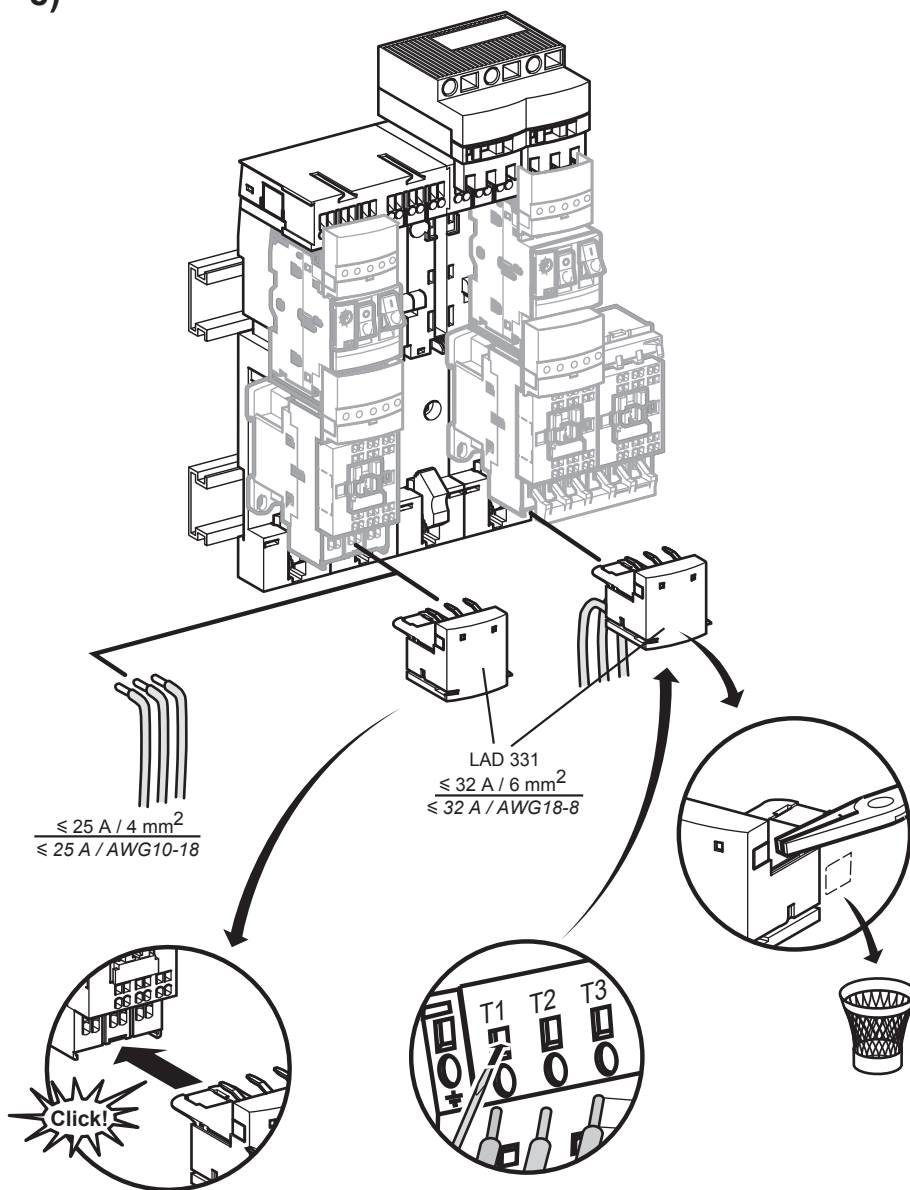

9)

mm  
in.

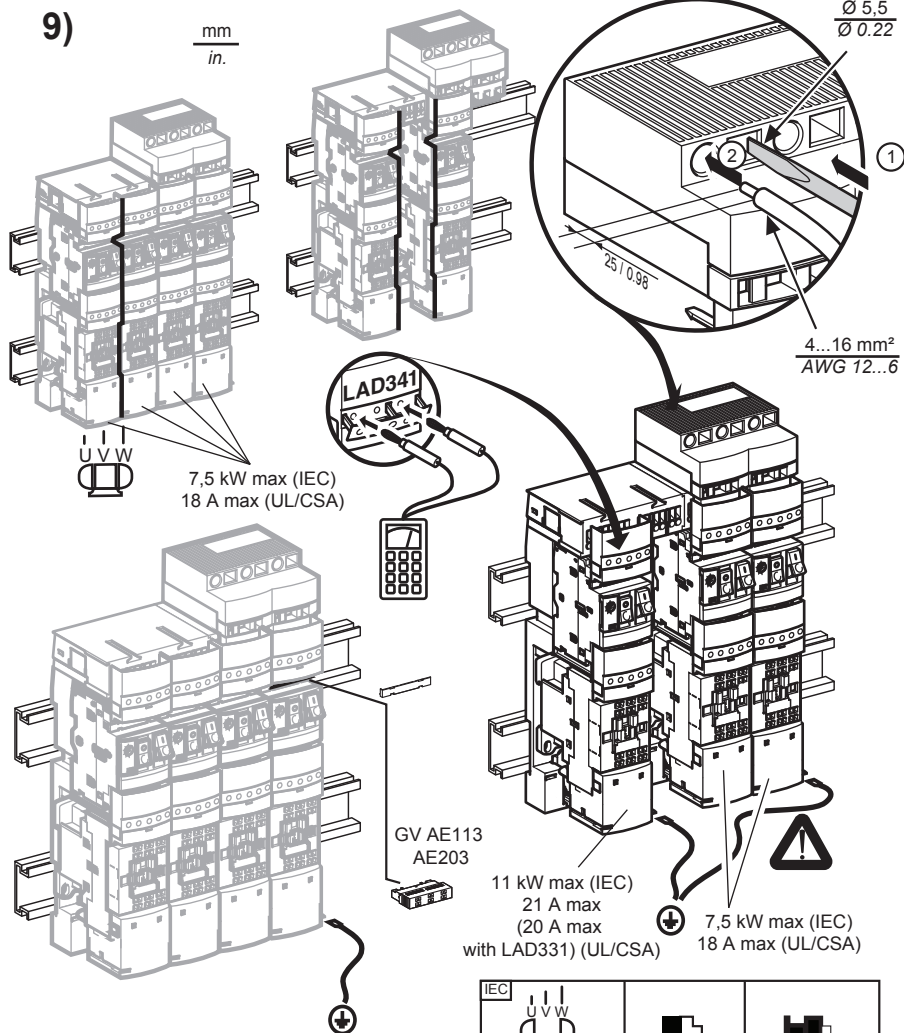

| IEC                                                                                           |      |                                                                                     |                                                                                     |
|-----------------------------------------------------------------------------------------------|------|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|
| <br>P 400V |      |  |  |
| KW                                                                                            | HP   |                                                                                     |                                                                                     |
| 0,37                                                                                          | 0.5  | GV2ME063                                                                            | LC1D093●●                                                                           |
| 0,55                                                                                          | 0.75 | GV2ME073                                                                            | LC1D093●●                                                                           |
| 0,75                                                                                          | 1    | GV2ME073                                                                            | LC1D093●●                                                                           |
| 1,1                                                                                           | 1.5  | GV2ME083                                                                            | LC1D093●●                                                                           |
| 1,5                                                                                           | 2    | GV2ME083                                                                            | LC1D093●●                                                                           |
| 2,2                                                                                           | 3    | GV2ME103                                                                            | LC1D093●●                                                                           |
| 3                                                                                             | 4    | GV2ME143                                                                            | LC1D093●●                                                                           |
| 4                                                                                             | 5.5  | GV2ME143                                                                            | LC1D093●●                                                                           |
| 5,5                                                                                           | 7.5  | GV2ME163                                                                            | LC1D123●●                                                                           |
| 7,5                                                                                           | 10   | GV2ME203                                                                            | LC1D183●●                                                                           |
| 9                                                                                             | 12   | GV2ME213                                                                            | LC1D253●●                                                                           |
| 11                                                                                            | 15   | GV2ME223                                                                            | LC1D253●●                                                                           |

