

**AVAILABLE
NOW**

S31 and S33 Safety Padlocks

Marine grade 316 stainless steel shackle provides superior corrosion resistance.

Includes labels in English, Spanish and French. Labels also available in Chinese, Russian, Portuguese, Japanese, German, Italian, Flemish, Czech, and Polish.

Photo ID label for S31, S33, 406 and 410. Label model S142 available August 2010.



Available Key Retaining (model S31) or Non-Key Retaining (model S33) for use with group lockout.



Laser engrave face and sides.
Faces: Up to 5 lines x 11 characters
Sides: Up to 3 lines x 19 characters


Patented

Available in 9 colors. Red, Yellow, Green, Blue, Black, Teal, Purple, Orange and White.

3/16" (4.76mm) shackle fits more places. Available in 1-1/2" (38mm) standard and tall 3" (76mm) heights.

Durable padlock weighs just 3 ounces, making it easy to carry many.

Special thermoplastic body offers superior performance against chemicals, moisture, heat, cold and UV. Operates from -70 to +350 degrees F (-56 to +176 degrees C).

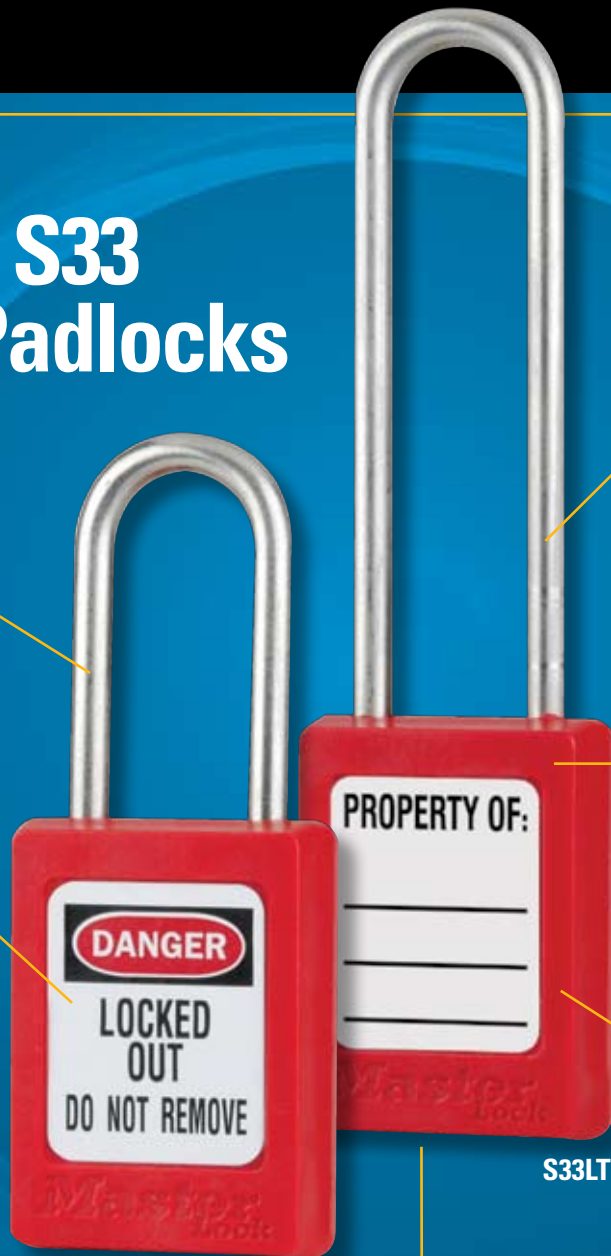

S31

S33LT


One employee, one key purity. "Safety" specific keyway for Keyed Alike and Keyed Different padlocks and another Safety specific keyway for Master Keyed systems means no inadvertent key interchange. Ensures your safety lockout system remains uncorrupted.



AVAILABLE
NOW

S31 and S33 Safety Padlocks

Model Number		Vertical Clearance (A)	Horizontal Clearance (B)	Shackle Diameter (C)	Body Width (D)	Body Height (E)
Key Retaining	Non-Key Retaining					
S31	S33	1-1/2" (38mm)	5/8" (15mm)	3/16" (4.76mm)	1-3/8" (35mm)	1-7/8" (48mm)
S31LT	S33LT	3" (76mm)				

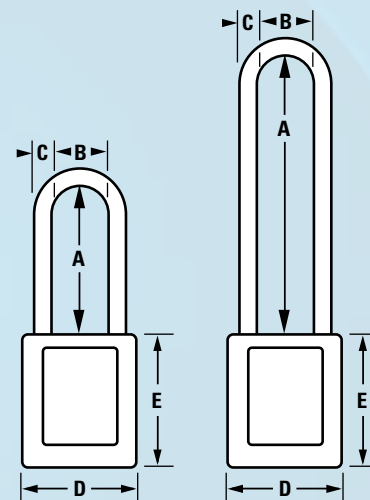

NEW

Lockout Products to Fit Smaller Diameter Lockout Points

S806 and S806CBL Adjustable Cable Lockout

- 5/32" x 6 foot (4mm x 1.8m) length cinch tight cable lockout
- Build to order, S806CBL, offers cable length from 2 to 50 foot (.6 to 15.2m)
- Patented



S431 Stainless Steel Lockout Hasp

- Marine grade 316 stainless steel offers superior corrosion resistance for extreme environments
- 5/32" (4mm) diameter hasp shackle fits more lockout applications
- Accepts up to 8 padlocks with shackles up to 5/16" (8mm)
- Patent Pending



S430 Adaptor Lockout Hasp

- 5/32" (4mm) diameter chrome plated steel hasp shackle fits more lockout applications
- Accepts up to 2 padlocks with shackle diameters up to 5/16" (8mm)
- Patent Pending

