 



TRANSPORTATION BASE

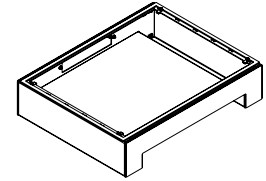

89129496

APPLICATION

PROLINE G2 Transportation Bases provide enhanced stability and forklift provisions for modular enclosures up to a maximum of 3000 mm (118.11) total width in a multiple-bay system.

FEATURES

- Can be used across bayed enclosures up to a maximum of 300mm (118.11in.) total width
- Maintains NEMA 12 rating without requiring gland plate
- Removable side cover plates allows wire access between bases

SPECIFICATIONS

- 10 gauge (3 mm), mild steel
- Can be configured in a variety of combinations
- Unique design allows forklift access from each end
- Gasket and installation hardware included

FINISH

- Polyester powder paint; RAL 9005 textured black standard
- Custom colors available

ACCESSORIES

Transportation Base Joining Kit, Side-to-Side

BULLETIN: P40

Standard Product

Catalog Number	W (mm)	W (in.)	D (mm)	D (in.)	Fits Frame WxD (mm)
P2BT45	411	16.2	467	18.4	400 x 500
P2BT46	411	16.2	567	22.3	400 x 600
P2BT64	611	24.1	367	14.4	600 x 400
P2BT65	611	24.1	467	18.4	600 x 500
P2BT66	611	24.1	567	22.3	600 x 600
P2BT68	611	24.1	767	30.2	600 x 800
P2BT84	811	31.9	367	14.4	800 x 400
P2BT85	811	31.9	467	18.4	800 x 500
P2BT86	811	31.9	567	22.3	800 x 600
P2BT88	811	31.9	767	30.2	800 x 800
P2BT810	811	31.9	967	38.1	800 x 1000
P2BT104	1011	39.8	367	14.4	1000 x 400
P2BT105	1011	39.8	467	18.4	1000 x 500
P2BT106	1011	39.8	567	22.3	1000 x 600
P2BT108	1011	39.8	767	30.2	1000 x 800
P2BT124	1216	47.9	367	14.4	1200 x 400
P2BT125	1216	47.9	467	18.4	1200 x 500
P2BT126	1216	47.9	567	22.3	1200 x 600
P2BT128	1216	47.9	767	30.2	1200 x 800
P2BT164	1616	63.6	367	14.4	1600 x 400
P2BT165	1616	63.6	467	18.4	1600 x 500
P2BT166	1616	63.6	567	22.3	1600 x 600
P2BT168	1616	63.6	767	30.2	1600 x 800
P2BT185	1816	71.5	467	18.4	1800 x 500
P2BT186	1816	71.5	567	22.3	1800 x 600
P2BT188	1816	71.5	767	30.2	1800 x 800

Model	Component	Type	Width	Depth	Catalog Number
P2	B	T	8	6	= P2BT86
PROLINE G2	Base	T = transportation base	mm	mm	
			18 = 1800	10 = 1000	
			16 = 1600	8 = 800	
			12 = 1200	6 = 600	
			10 = 1000	5 = 500	
			8 = 800	4 = 400	
			6 = 600		
			4 = 400		

NOTE: Not every combination is available as a standard product.

TRANSPORTATION BASE JOINING KIT, SIDE-TO-SIDE



APPLICATION

The PROLINE G2 Transportation Base Joining Kit, Side-to-Side interconnects transportation bases while maintaining the NEMA Type 12 rating.

FEATURES

- Maintains NEMA 12 rating between Fully-Sealed Plinth bases
- Allows for sealed cable routing between joined cabinets

SPECIFICATIONS

- Gasket and installation hardware included
- Furnished grommet applied to edge of wire feed

BULLETIN: P40

Catalog Number	Description
P2AJT	Transportation Base Joining Kit, Side-to-Side

