

**BARRIER PANEL**



**APPLICATION**

Barrier Panels are designed to be used as buffers between joined or ganged enclosure systems. When mounted to the enclosure, they maintain enclosure environmental integrity.

**FEATURES**

- Barrier between joined or ganged enclosure

**SPECIFICATIONS**

- 16 gauge steel
- All mounting hardware included


**FINISH**

- Polyester powder paint; RAL 7035 textured light gray standard
- Custom colors available

**BULLETIN: P40**

Standard Product

Catalog Number	H (mm)	H (in.)	W (mm)	W (in.)	Fits Frame HxW (mm)
P2CB125	1183	46.6	459	18.1	1200x500
P2CB126	1183	46.6	559	22.0	1200x600
P2CB128	1183	46.6	759	29.9	1200x800
P2CB145	1383	54.4	459	18.1	1400x500
P2CB148	1383	54.4	759	29.9	1400x800
P2CB164	1583	62.3	359	14.1	1600x400
P2CB165	1583	62.3	459	18.1	1600x500
P2CB166	1583	62.3	559	22.0	1600x600
P2CB168	1583	62.3	759	29.9	1600x800
P2CB184	1783	70.2	359	14.1	1800x400
P2CB185	1783	70.2	459	18.1	1800x500
P2CB186	1783	70.2	559	22.0	1800x600
P2CB188	1783	70.2	759	29.9	1800x800
P2CB204	1983	78.1	359	14.1	2000x400
P2CB205	1983	78.1	459	18.1	2000x500
P2CB206	1983	78.1	559	22.0	2000x600
P2CB208	1983	78.1	759	29.9	2000x800
P2CB2010	1983	78.1	959	37.8	2000x1000
P2CB225	2183	85.9	459	18.1	2200x500
P2CB226	2183	85.9	559	22.0	2200x600
P2CB228	2183	85.9	759	29.9	2200x800
P2CB2210	2183	85.9	959	37.8	2200x1000

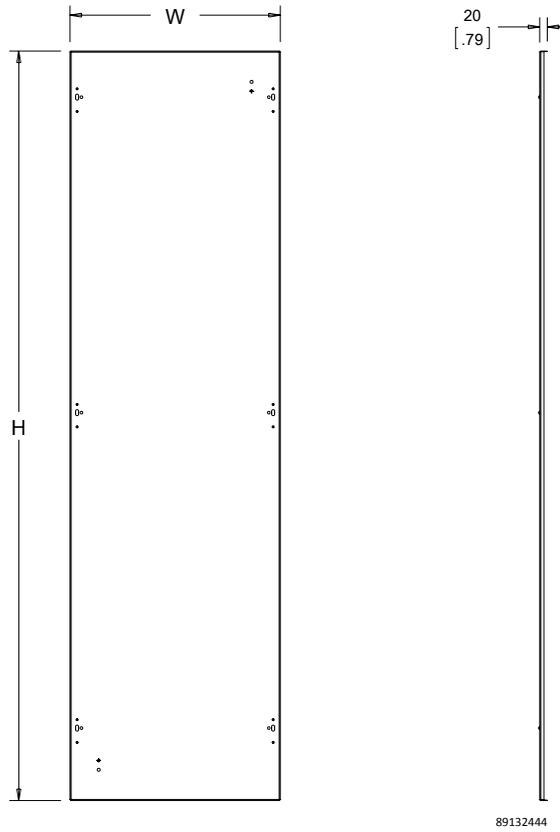

Model	Component	Type	Height	Depth	Specialty	Catalog Number
<b>P2</b>	<b>C</b>	<b>B</b>	<b>20</b>	<b>6</b>	<b>Blank</b>	<b>= P2CB206</b>
PROLINE G2	Cover	Blank = cover S = side cover B = barrier panel	mm 22 = 2200 20 = 2000 18 = 1800 16 = 1600 14 = 1400 12 = 1200 10 = 1000 8 = 800 6 = 600	mm 10 = 1000 8 = 800 6 = 600 5 = 500 4 = 400	Blank = standard HF = EMC protected	

NOTE: Not every combination is available as a standard product.