

- LG42-SROC Finish(C)
- LG42-SROK Finish(K)
- LG42-SROY Finish(Y)
- LG42-SR5C Finish(C)

## Specifications

- Single Control
- 3-Hole Installation
- Pforever Seal

### Features

- 1.2 GPM Flow Rate
- All Metal Construction
- Lever Handle
- Includes Metal Supply Nuts
- 3-Hole Installation
- Metal Pop-Up (SRO\* Only)
- 50/50 Pop-Up (SR5C Only)
- Decorative Arc Spout
- Fixed Spout
- Pforever Seal Ceramic Disc Valve
- Pforever Warranty®


### Code Compliance

Pfister products are designed and manufactured in compliance with the following standards and codes:

- IAPMO Certified
- CSA B125 Certified
- ASME A112.18.1
- NSF 61/9 Annex G (Low lead)
- Cal Green Compliant
- CEC Compliant
- EPA WaterSense Certification 1.2 gpm, 4.5L/Min
- ADA Compliant-ANSI A117.1 (Lever handles only)



## Dimensions

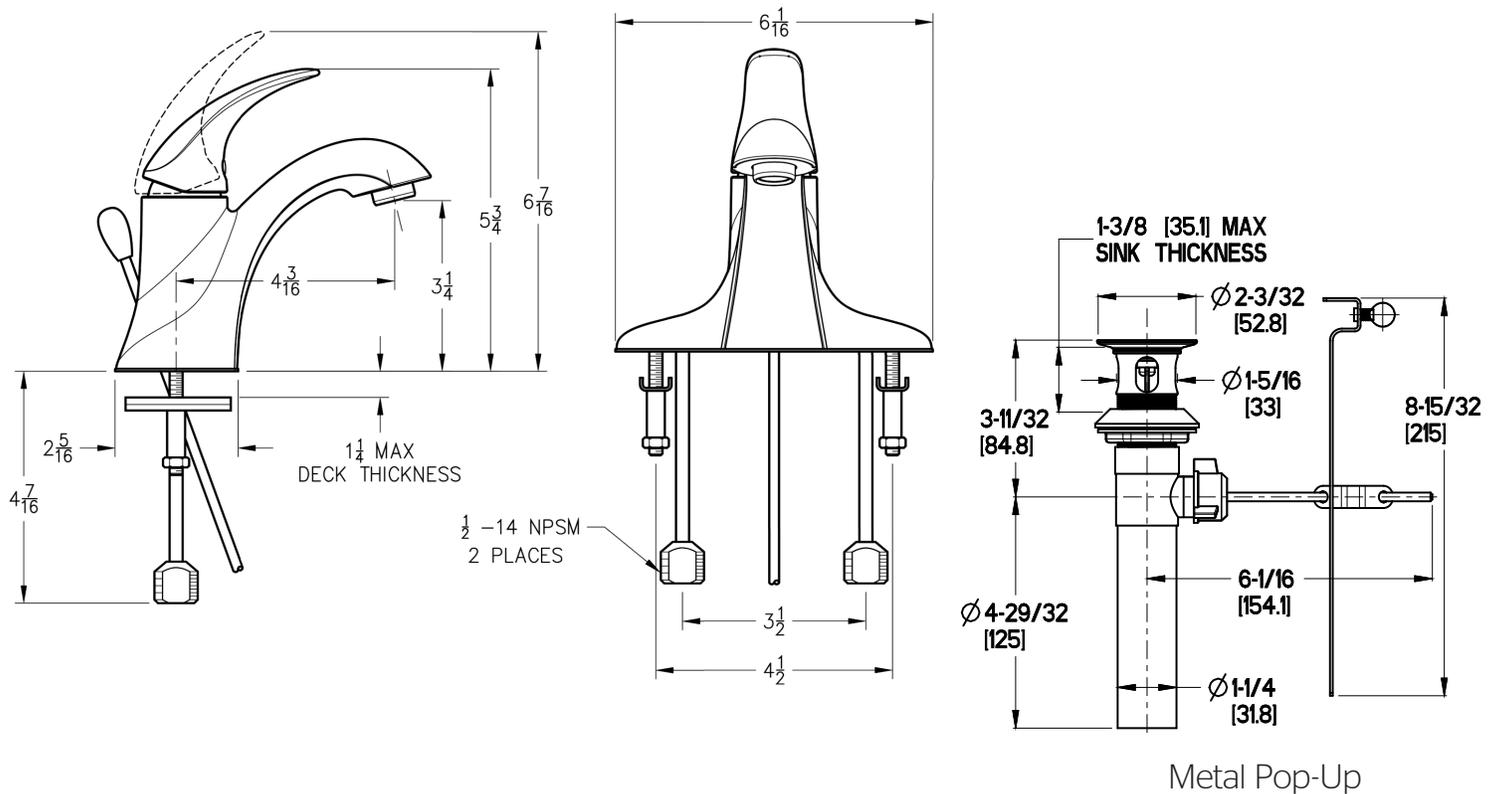

Ø1 Min to Ø1-1/2 Max. Deck Hole Openings