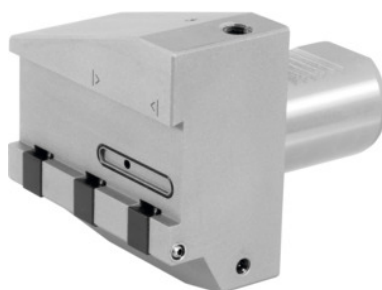


Garant**Eco parting-off toolholder overhead with ICS, Shank Ø d1: 40mm****Order data**

Order number	319133 40
GTIN	4045197717252
Item class	31V

Description**Version:**

- With special adjustable ball type coolant nozzle for optimum cooling of the cutting edge, irrespective of the groove depth.
- This reduces the temperature both at the main cutting edge and the auxiliary cutting edge, and permits a significant increase in cutting speed.
- Rigid toolholder for parting-off tools.
- Blade clamped using clamping plate.

Application:

Allows parting-off tools of different makes to be used.

Note:

Screw plug for ball spray nozzle included. If conventional grooving tools are used, the lateral coolant transfer is blocked by the grooving tool. Suitable clamping claws No. 279840 2 and suitable screws No. 279815 14. See spare parts list.

Technical description

Shank Ø D ₁	40 mm
Colour code for VDI shanks	VDI 40
L ₂	85 mm

L ₁	54 mm
suitable for blade height	32 mm
Height H ₁	73 mm
Height H ₂	47 mm
Type of product	VDI parting-off toolholder