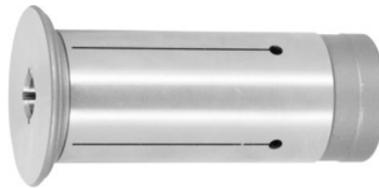


Garant

Slotted reducing adapter with cooling, Ø 12 mm, Clamping range Ø D1: 5mm


Order data

Order number	302135 5
GTIN	4045197763211
Item class	31G

Description
Version:

With cooling channel slots.

Application:

- **For drilling, reaming, milling, and tool sharpening.**
- **Very high flexibility due to reduction in clamping diameter.**
- **Very high torque guarantees a higher volume of metal removal compared to direct clamping.**
- **Concentricity $\pm 5 \mu\text{m}$ (system accuracy at $3 \times D$).**
- **Concentricity $\pm 2 \mu\text{m}$ (for reducing adapter).**
- **Can be used in all commercially available hydraulic chucks.**

Suitable for:

Hydraulic chuck **with clamping Ø 12 mm.**

Technical description

Ø D	12 mm
Overall length L	47 mm
Clamping Ø D ₁	5 mm
Product name attribute	Ø 12 mm
Concentricity system	5 μm
Type of product	Reducing adapter

