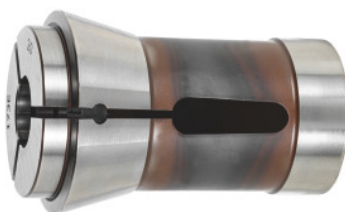


**Push-out collet, round, to DIN 6343, 173 E, Clamping Ø: 6mm****Order data**

|              |               |
|--------------|---------------|
| Order number | 329560 6      |
| GTIN         | 4067263110750 |
| Item class   | 32Z           |

**Description****Version:**

Collets, **round profile in 1 mm increments. Please specify required clamping Ø with order.**

**Standard:**

**DIN 6343**

**Accuracy:**

**Concentricity tolerances:** D = 1 to 10 mm = 0.02 mm D = 10 to 30 mm = 0.03 mm D = 30 to 60 mm = 0.04 mm

**Note:**

Other diameters and profiles (e.g. square or hexagon) **on request!**

Profile Ø 1.0 – 8.0 mm smooth. From Ø 8.5 mm with transverse serrations.

**Technical description**

|                  |            |
|------------------|------------|
| Angle $\alpha$   | 15 degrees |
| Overall length L | 94 mm      |
| F                | 48 mm      |
| K                | 60 mm      |
| A                | 50 mm      |
| Type             | 173 E      |

Type of product

Collet