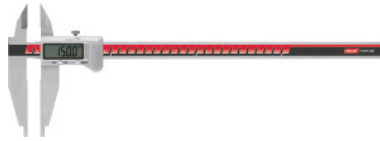


**Digital caliper with measuring tips, Measuring range: 300mm****Order data**

Order number	415611 300
GTIN	4045197301444
Item class	42A

Description**Version:**

Direct reading from large and clear digital display. **With sturdy metal housing.**

Supplied with:

1 battery No. 081560 size LR44.

Technical description

Measuring range	0 - 300 mm
Jaw length	90 mm
Internal jaw Ø	10 mm
Reversible reading	mm / inch
Calibration	A1
Scale divisions	0.0005 in
Scale divisions	0.01 mm
Article no of the battery / rechargeable battery fitted	081560 LR44
Number of batteries contained	1
Power supply	Battery-powered
Measurement deviation E MPE	± 0.04 mm
Standard	ISO 13385

Measurement technology	digital
Material	Stainless steel, INOX
all parts	hardened
Packaging	sturdy box
Type of product	Workshop calipers

Services

DAkkS calibrationCalipers / depth gauges maximum measuring range 300 mm	021010 300
CalibrationCalipers / depth gauges maximum measuring range 300 mm	021000 300

Accessories

Screw for depth gauge holder	412230
Button cell / special battery Battery type LR44	081560 LR44