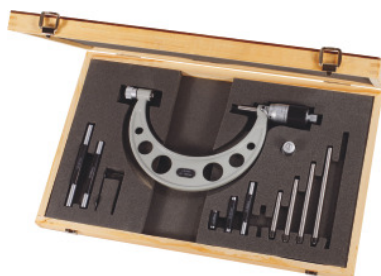


**Large external micrometer 1/100 graduations, Measuring range: 100-200mm****Order data**

Order number	420770 100-200
GTIN	4045197203915
Item class	42B

Description**Version:**

Hardened and ground measuring spindle. Precision lapped, carbide-tipped measuring faces. Locking by locking lever. Large barrel with 1/100 scale and ratchet. Lightweight external micrometers, hammer finish.

Technical description

Spindle travel	25 mm
Micrometer barrel graduations	1/100 mm
Measuring range	100 - 200 mm
Spindle Ø	8 mm
Barrel Ø	25 mm
Number of micrometer standards	4
Number of measuring tips	4
Scale divisions	0.01 mm
Calibration	S3
Standard	DIN 863

Measurement technology	analogue
Packaging	sturdy box
Type of product	External tube micrometer

Services

CalibrationExternal micrometers with extensions Measuring range 100-200 mm	020450 100-200
---	----------------

Accessories

Micrometer setting standard overall length 100 mm	421100 100
---	------------